


L34115



Female wirable connectors

SDOGB030ALSFKPG

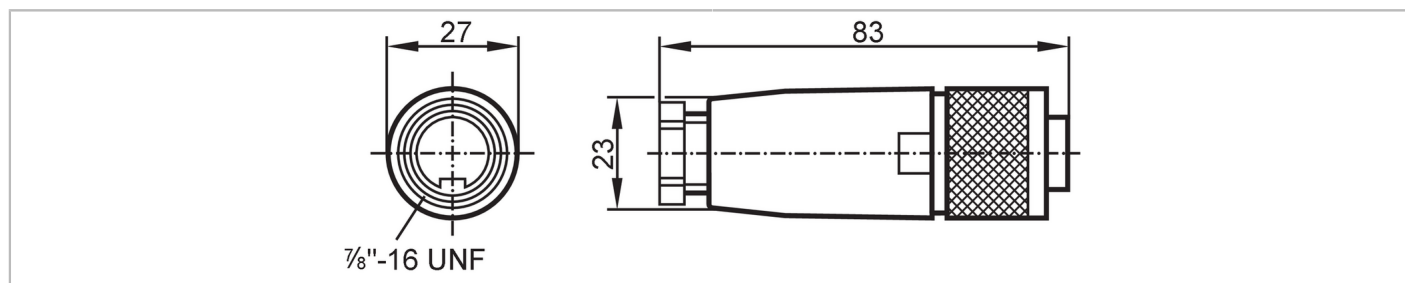

Application	
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 600 AC
Max. current load total [A]	12
Operating conditions	
Ambient temperature [°C]	-40...90
Protection	IP 67
Mechanical data	
Weight [g]	45.359
Dimensions [mm]	27 x 27 x 83
Molded-body material	PA 6.6
Material nut	aluminum, black anodized
Remarks	
Remarks	Pin 2 leading
Pack quantity	1 pcs.

Electrical connection
 terminals: ...1.5 mm²; Cable sheath: Ø 5...13 mm

Electrical connection - Socket
 Connector: 1 x 7/8", straight; coding: A; Contacts: 3; Moulded body: PA 6.6; Locking: aluminum, black anodized

