


L34321



Female wirable connectors

SDOGH050MSSFKPG

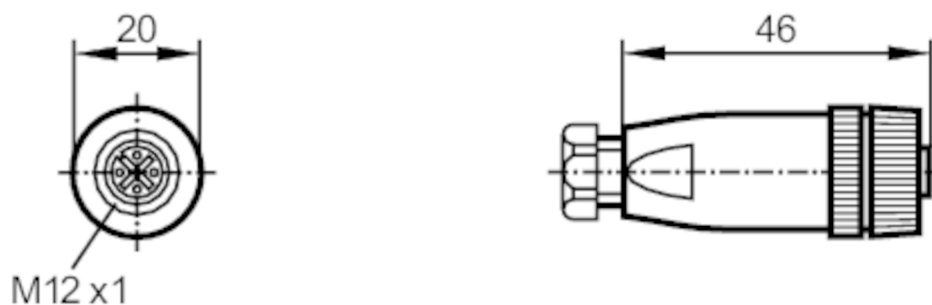

Application

System	Free from silicone; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 125 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68

Mechanical data

Weight	[g]	27.216
Dimensions	[mm]	20 x 20 x 46
Material		PA
Molded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

L34321



Female wirable connectors

SDOGH050MSSFKPG

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

