


MK5139



T-slot cylinder sensor

MKT3020BBPKG/A/0,3M/ZH/US

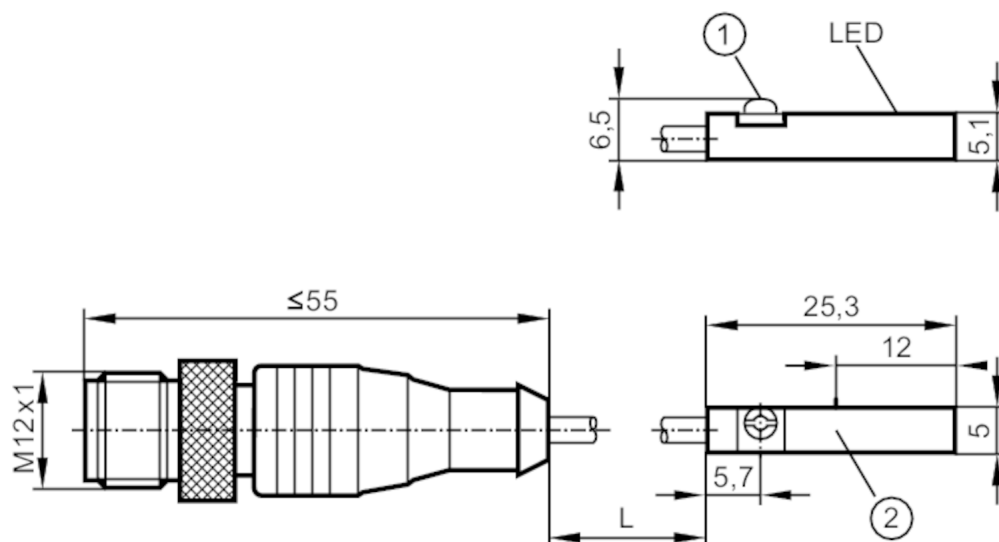

- 1 Fastening clamp
2 sensing face



Product characteristics

Electrical design	PNP
Output function	normally open
Dimensions [mm]	25 x 5 x 6.5

Electrical data

Operating voltage [V]	10...30 DC; (cULus - Class 2 source required)
Current consumption [mA]	< 10
Protection class	III
Reverse polarity protection	yes
Max. power-on delay time [ms]	30

Outputs

Electrical design	PNP
Output function	normally open
Max. voltage drop switching output DC [V]	2.5
Permanent current rating of switching output DC [mA]	100
Switching frequency DC [Hz]	6000
Short-circuit protection	yes
Overload protection	yes

Monitoring range

Magnetic sensitivity [mT]	2
Travel speed [m/s]	> 10

Accuracy / deviations

Hysteresis [mm]	< 1
-----------------	-----

MK5139



T-slot cylinder sensor

MKT3020BBPKG/A/0,3M/ZH/US

Repeatability	[mm]	< 0.2
---------------	------	-------

Operating conditions

Ambient temperature	[°C]	-25...85
---------------------	------	----------

Protection	IP 65; IP 67
------------	--------------

Tests / approvals

EMC	EN 61000-4-2 ESD	- CD / 8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF conducted	10 V
	EN 55011	class B

MTTF	[years]	2064
------	---------	------

UL approval	UL approval number	C003
-------------	--------------------	------

Mechanical data

Weight	[g]	21.2
--------	-----	------

Mounting	flush mountable
----------	-----------------

Type of mounting	fastening clamp with combined slot / hexagon socket, width across flats 1.5
------------------	---

Cylinder type	T-slot cylinders
---------------	------------------

Dimensions	[mm]	25 x 5 x 6.5
------------	------	--------------

Material	housing: PA; Fastening clamp: stainless steel
----------	---

Displays / operating elements

Display	Switching status	1 x LED, yellow
---------	------------------	-----------------

Accessories

Items supplied	rubber memory stop: 1
	cable clip: 1

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Cable: 0.3 m, PUR

Connector: 1 x M12; coding: A; Locking: Knurled nut, rotatable



MK5139



T-slot cylinder sensor

MKT3020BBPKG/A/0,3M/ZH/US

Connection

