


MR0121



T-slot cylinder sensor with reed contact

MRT3021BBKOA/R/0,3M/ZH/US

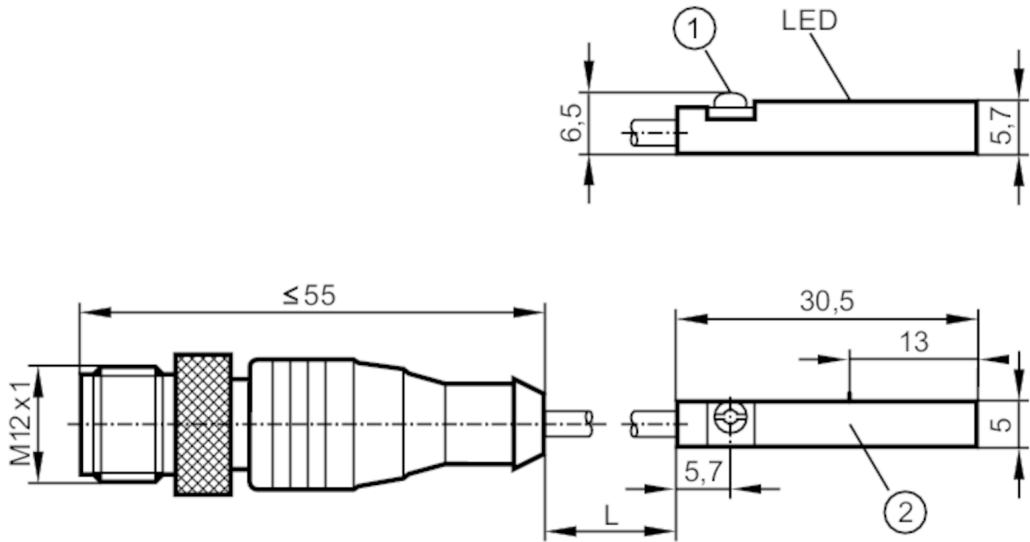

- 1 Fastening clamp with combined slot / hexagon socket head
hexagonal socket AF 1.5
2 sensing face



Product characteristics

Electrical design	PNP
Output function	normally open
Dimensions [mm]	30.5 x 5 x 6.5

Electrical data

Operating voltage [V]	5...50 AC/DC; (External protective circuit for inductive load (valve, contactor, etc.) necessary. ; UL - Class 2 source required)
Protection class	III
Reverse polarity protection	yes
Reverse polarity protection	no

Outputs

Electrical design	PNP
Output function	normally open
Max. voltage drop switching output DC [V]	1
Max. voltage drop switching output AC [V]	1
Permanent current rating of switching output AC [mA]	350
Permanent current rating of switching output DC [mA]	500
Switching frequency AC [Hz]	1000
Switching frequency DC [Hz]	1000
Max. switching power [W]	10
Short-circuit protection	no
Short-circuit proof	no

MR0121



T-slot cylinder sensor with reed contact

MRT3021BBKOA/R/0,3M/ZH/US

Overload protection	no	
Monitoring range		
Magnetic sensitivity	[mT]	2.1
Travel speed	[m/s]	10
Accuracy / deviations		
Hysteresis	[mm]	1
Repeatability	[mm]	< 0.2
Reaction times		
Max. fall time	[ms]	0.1
Max. make time incl. bounce	[ms]	0.6
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection	IP 65; IP 67	
Tests / approvals		
EMC	EN 61000-4-2 ESD	- CD / 8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF conducted	10 V
	EN 55011	class B
MTTF	[years]	20385
UL approval	UL approval number	C004
Mechanical data		
Weight	[g]	21.3
Mounting	flush mountable	
Cylinder type	T-slot cylinders	
Dimensions	[mm]	30.5 x 5 x 6.5
Material	PA; Fastening clamp: stainless steel	
Switching cycles when connected to PLC	[Mio]	40
Displays / operating elements		
Display	Switching status	1 x LED, yellow
Electrical connection		
Required protection	miniature fuse to IEC60127-2 sheet 1; ≤ 0,75 A; fast acting; DC operation; ≤ 0,6 A; fast acting; AC operation	
Accessories		
Items supplied	rubber memory stop: 1	
	cable clip: 1	
Remarks		
Pack quantity	1 pcs.	

MR0121




T-slot cylinder sensor with reed contact

MRT3021BBKOA/R/0,3M/ZH/US

Electrical connection - plug

Cable: 0.3 m, PUR

Connector: 1 x M12; coding: A; Locking: Knurled nut, rotatable

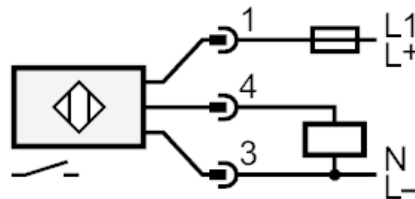

Note miniature fuse to IEC60127-2 sheet 1
 ≤ 0.75 A fast acting DC operation
 ≤ 0.6 A fast acting AC operation