




Diffuse reflection sensor

ORT-V

Article no longer available - archive entry

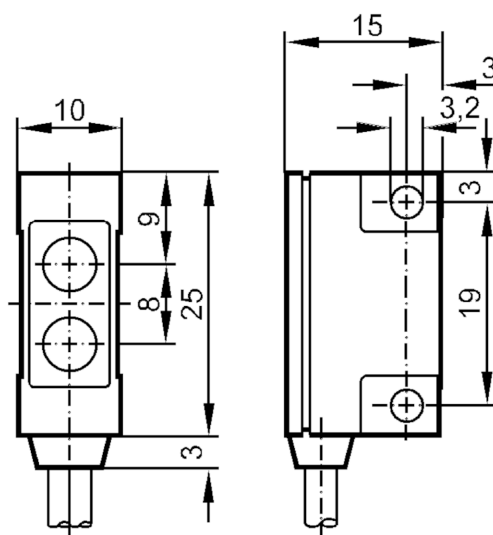

Receiver in upper lens
transmitter in lower lens

Product characteristics

Housing rectangular

Application

Function principle Diffuse reflection sensor

Electrical data

Connection at circuit amplifier yes

Switching amplifiers Connection at circuit amplifier OV5012, OV0010

Outputs

Short-circuit protection no

Overload protection no

Monitoring range

Range [mm] < 300; (white paper 200 x 200 mm)

Operating conditions

Protection IP 67

Mechanical data

Housing rectangular

Dimensions [mm] 25 x 10 x 15

Material PPO modified

Accessories

Items supplied Angle bracket: 1, E20212

Remarks

Pack quantity 1 pcs.

OR0016




Diffuse reflection sensor

ORT-V

Electrical connection

Cable: 2 m; 1 x 0.14 mm²

Connection

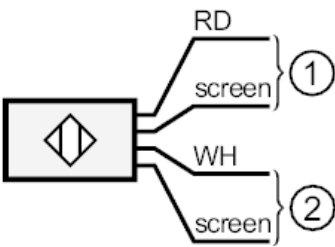

- 1 = transmitter
- 2 = receiver
- Core colors :
- RD = red
- WH = white
- screen = screen