


U10000



Mounting adapter for capacitive sensors

WELL, M18, 3/4" NPT, PTFE

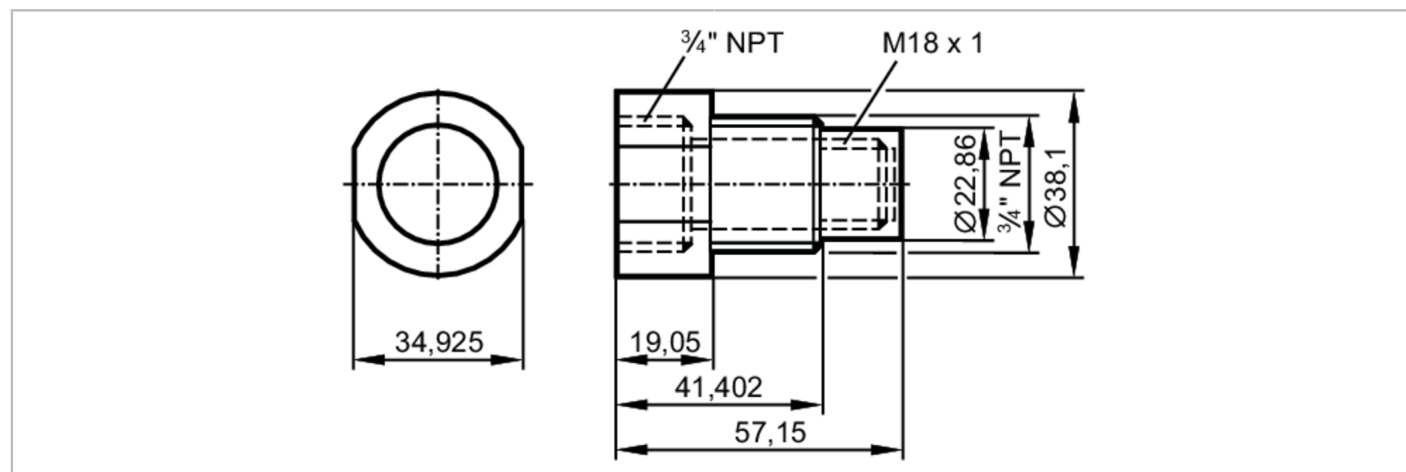

Application

Design	for types M18
Pressure rating [bar]	6.9

Operating conditions

Ambient temperature [°C]	-25...246
Note on ambient temperature	-25...260 for short duration

Mechanical data

Weight [g]	20
Material	PTFE
Process connection	3/4" NPT

Remarks

Pack quantity	1 pcs.
---------------	--------