


W10114



Male receptacle

RSTGH040ALS00.3-04

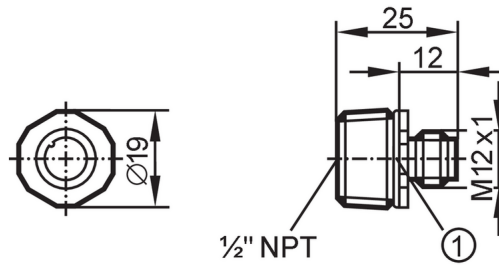

1 O-ring

Electrical data

Operating voltage [V] < 250 DC

Operating conditions

Ambient temperature [°C] -20...90

Mechanical data

Weight [g] 22.68

Mounting thread 1/2" NPT

Material aluminum anodized 10...20 µm

Molded-body material aluminum, anodized 10...20 µm

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.34 mm² / AWG 22

Electrical connection - plug

Connector: 1 x M12; coding: A; Contacts: 4; Moulded body: aluminum, anodized 10...20 µm



Connection

1	BN
2	WH
3	BU
4	BK

Core colors :
 BK = black
 BN = brown
 BU = blue
 WH = white