


# W80510



## Female cordset

ADOGF030MSS0005E03

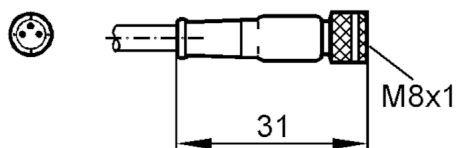

### Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
-------------------	-----	-------------------

### Operating conditions

Ambient temperature	[°C]	-25...100
---------------------	------	-----------

Protection		IP 68
------------	--	-------

### Mechanical data

Weight	[g]	136.078
--------	-----	---------

Material		TPE
----------	--	-----

Molded-body material		TPE
----------------------	--	-----

Material nut		brass, nickel-plated
--------------	--	----------------------

### Remarks

 
Pack quantity		1 pcs.
---------------	--	--------

### Electrical connection

Cable: 5 m, PVC, yellow, Ø 4.3 mm; 3 x 0.25 mm<sup>2</sup> (128 x Ø 0.05 mm )

### Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPE; Locking: brass, nickel-plated




# W80510



## Female cordset

ADOGF030MSS0005E03

### Connection

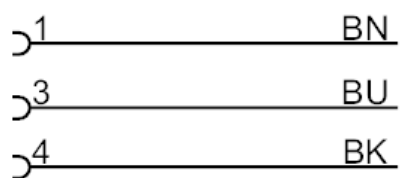

	Core colors :
BK =	black
BN =	brown
BU =	blue