


W80603



Female cordset

AD0GB030MKS0010X03

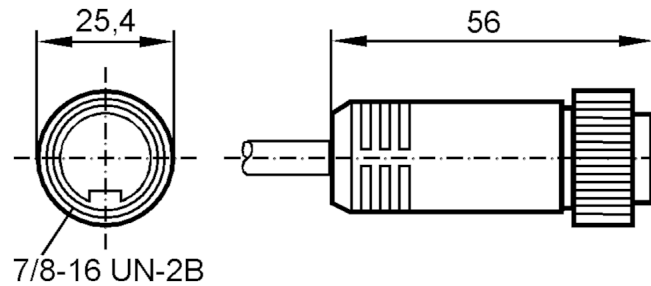

Application

Special feature	gold-plated contacts
Application	Industrial applications

Electrical data

Operating voltage	[V]	< 600 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...90
Protection		IP 68

Mechanical data

Weight	[g]	1415.207
Material		PVC
Molded-body material		PVC
Material nut		zinc, epoxy coated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PVC, yellow, Ø 6 mm; 3 x 1.5 mm² / AWG 16

Electrical connection - Socket

 Connector: 1 x 7/8", straight; coding: A; Contacts: 3, gold-plated; Moulded body: PVC; Locking: zinc, epoxy coated




W80603



Female cordset

AD0GB030MKS0010X03

Connection

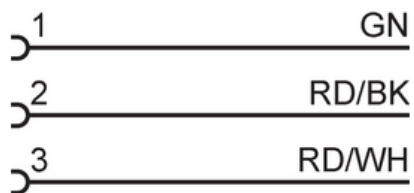

GN =
RD/BK =
RD/WH =

Core colors :
green
red/black
red/white