


W80603



Female cordset


AD0GB030MKS0010X03

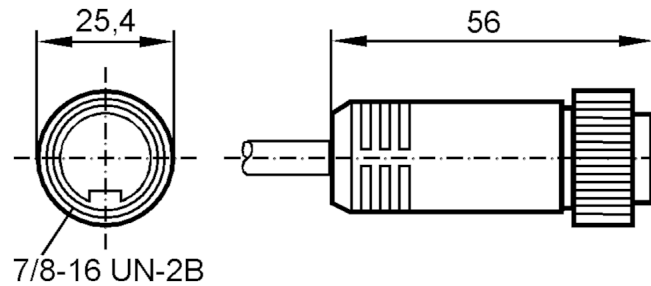

Application	
Special feature	gold-plated contacts
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 600 AC/DC
Operating conditions	
Ambient temperature [°C]	-20...90
Protection	IP 68
Mechanical data	
Weight [g]	1415.207
Material	PVC
Molded-body material	PVC
Material nut	zinc, epoxy coated
Remarks	
Pack quantity	1 pcs.

Electrical connection
 Cable: 10 m, PVC, yellow, Ø 6 mm; 3 x 1.5 mm² / AWG 16

 Electrical connection - Socket
 Connector: 1 x 7/8", straight; coding: A; Contacts: 3, gold-plated; Moulded body: PVC; Locking: zinc, epoxy coated




W80603



Female cordset

AD0GB030MKS0010X03

Connection

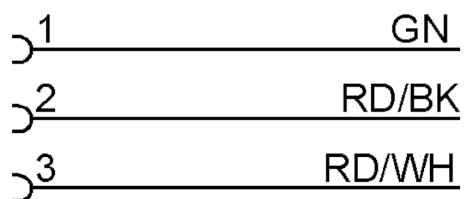

GN =	Core colors :	green
RD/BK =		red/black
RD/WH =		red/white