


# W80650



## Female cordset

AD0GB050MKS0002X05

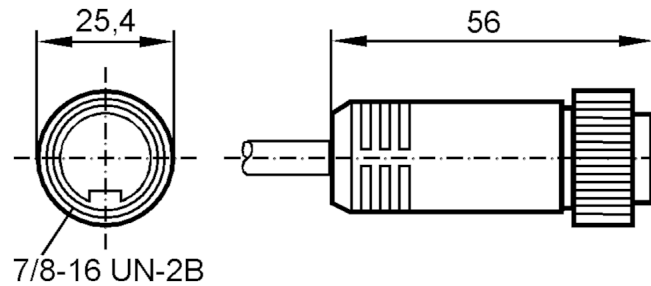

### Application

Special feature	gold-plated contacts
Application	Industrial applications

### Electrical data

Operating voltage	[V]	< 600 AC/DC
-------------------	-----	-------------

### Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

### Mechanical data

Weight	[g]	426.376
Material		PVC
Molded-body material		PVC
Material nut		zinc, epoxy coated

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 2 m, PVC, yellow, Ø 12.7 mm; 5 x 1.5 mm<sup>2</sup> / AWG 16

### Electrical connection - Socket

Connector: 1 x 7/8", straight; coding: A; Contacts: 5, gold-plated; Moulded body: PVC; Locking: zinc, epoxy coated




# W80650



## Female cordset

AD0GB050MKS0002X05

### Connection

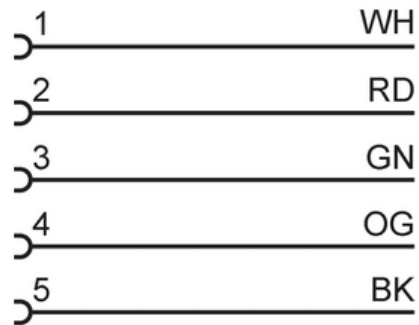

Core colors :  
BK = black  
GN = green  
RD = red  
OG = orange  
WH = white