


W80655

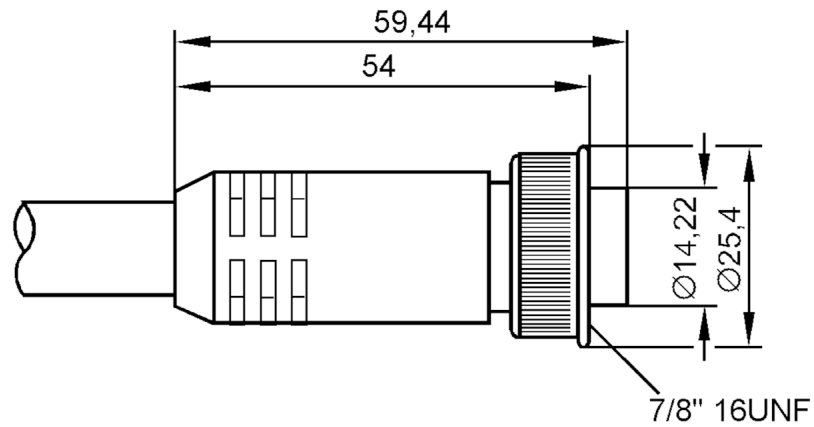

Female cordset

AD0GB050MKS0004X05



Application

Application Industrial applications

Electrical data

Operating voltage [V] < 300 AC/DC

Operating conditions

Ambient temperature [°C] -20...105

Protection IP 68

Mechanical data

Weight [g] 381.017

Dimensions [mm] 25.4 x 25.4 x 59.44

Molded-body material PVC

Material nut zinc, epoxy coated

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 4 m, PVC, yellow, Ø 7.12 mm; 5 x 0.5 mm² / AWG 20

Electrical connection - Socket

Connector: 1 x 7/8", straight; coding: A; Contacts: 5; Moulded body: PVC; Locking: zinc, epoxy coated




W80655



Female cordset

AD0GB050MKS0004X05

Connection

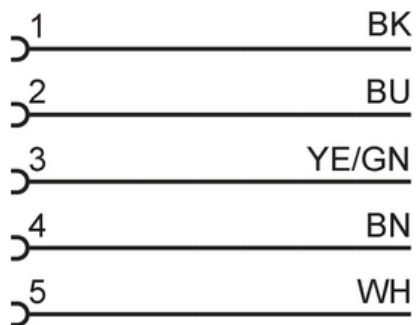

Core colors :
BK = black
BN = brown
BU = blue
GN/YE = green/yellow
WH = white