


W80657



Female cordset

ADOAB050MKS0004X05

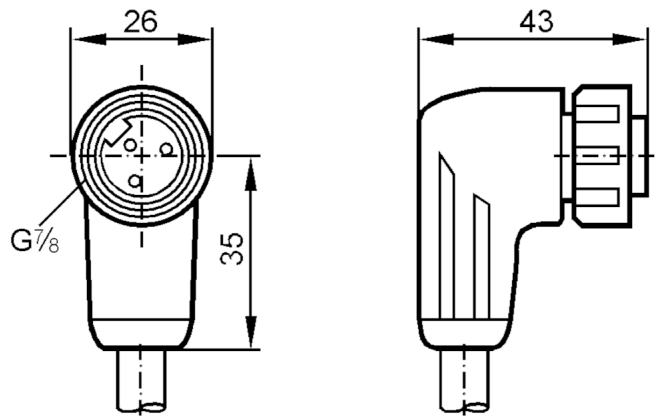

Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	807.394
Dimensions	[mm]	43 x 26 x 35
Material		PVC
Molded-body material		PVC
Material nut		diecast zinc, epoxy coated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 4 m, PVC, yellow, Ø 7.2 mm; 3 x 0.75 mm ² (16 x Ø 0.5 mm)		
Electrical connection - Socket		
Connector: 1 x 7/8", angled; coding: A; Moulded body: PVC; Locking: diecast zinc, epoxy coated		




W80657



Female cordset

ADOAB050MKS0004X05

Connection

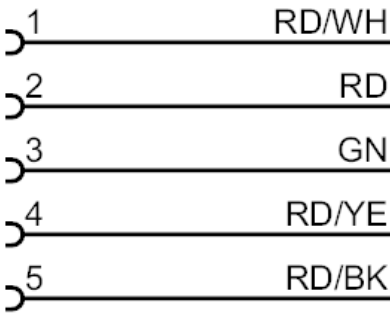

	Core colors :
BK =	black
GN =	green
RD =	red
WH =	white
YE =	yellow