


W80667



Female cordset

AD0GB050MKS0005X05

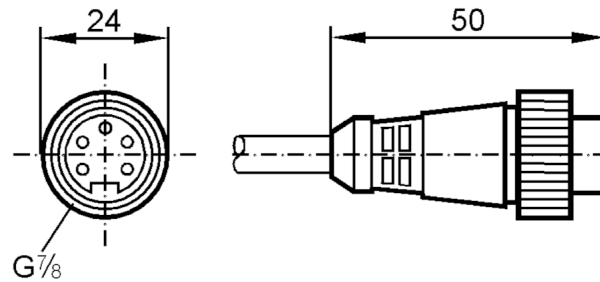

Application

Application Industrial applications

Electrical data

Operating voltage [V] < 250 AC

Operating conditions

Ambient temperature [°C] -40...90

Protection IP 68

Mechanical data

Weight [g] 381.017

Dimensions [mm] 24 x 24 x 50

Molded-body material TPU (urethane)

Material nut TPU (urethane)

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, PVC; 5 x 0.75 mm² / AWG 18

Electrical connection - Socket

Connector: 1 x 7/8", straight; coding: A; Contacts: 5; Moulded body: TPU (urethane); Locking: TPU (urethane)




W80667



Female cordset

AD0GB050MKS0005X05

Connection

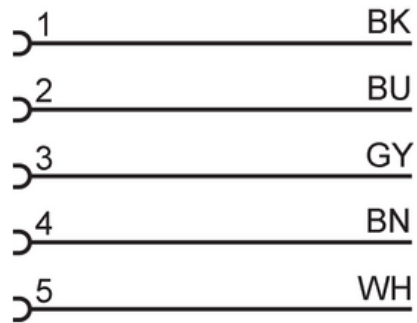

Core colors :
BK = black
BN = brown
BU = blue
GY = grey
WH = white