


ZH4114



Connection cable

VSTGX080MSS0005K08STGP080-S

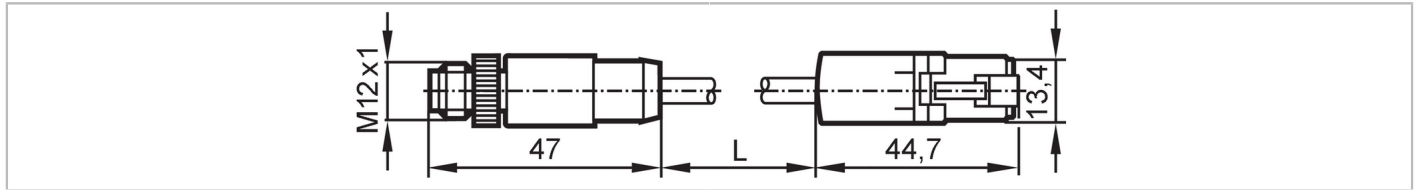

Application

Design	Ethernet cable, X-coded
Application	Industrial applications; Cross-over patch cable; Patch cable

Operating conditions

Ambient temperature	[°C]	-25...90
Note on ambient temperature		-25...70 (RJ45)
Protection		IP 67; (RJ45: IP 20)

Mechanical data

Weight	[g]	260
Material		PUR / TPU
Molded-body material		TPU (urethane) / PA
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug


Connector: 1 x M12, straight; coding: X; Contacts: 8; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Tightening torque: 0.4 Nm



Electrical connection

Cable: 5 m, PVC, blue, Ø 6.4 mm; 4 x 2x0.14 mm²

Connection

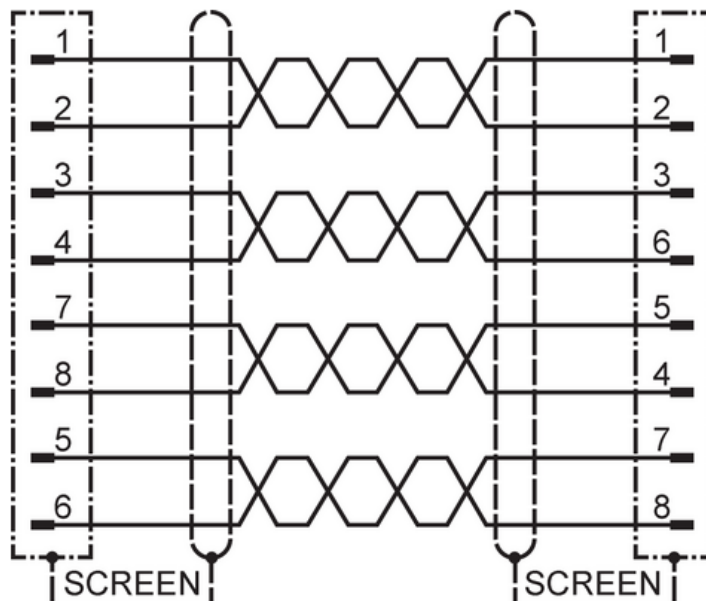

ZH4114



Connection cable

VSTGX080MSS0005K08STGP080-S

Electrical connection - plug

Connector: 1 x RJ45, straight; Contacts: 8; Moulded body: PA

