


ZH4116



Connection cable

VDOGX080MSS0010K08STGP080-S

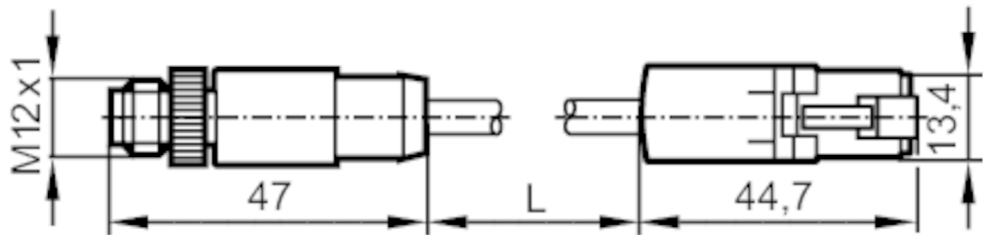

Application		
Design		Ethernet cable, X-coded
Application		Cross-over patch cable; Patch cable
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67; (RJ45: IP 20)
Mechanical data		
Weight	[g]	460
Material		PUR / TPU
Molded-body material		TPU (urethane) / PA
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		
Connector: 1 x M12, straight; coding: X; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Tightening torque: 0.4 Nm		



ZH4116




Connection cable

VDOGX080MSS0010K08STGP080-S

Electrical connection

Cable: 10 m, PVC, blue, Ø 6.4 mm; 4 x 2x0.14 mm²

Connection

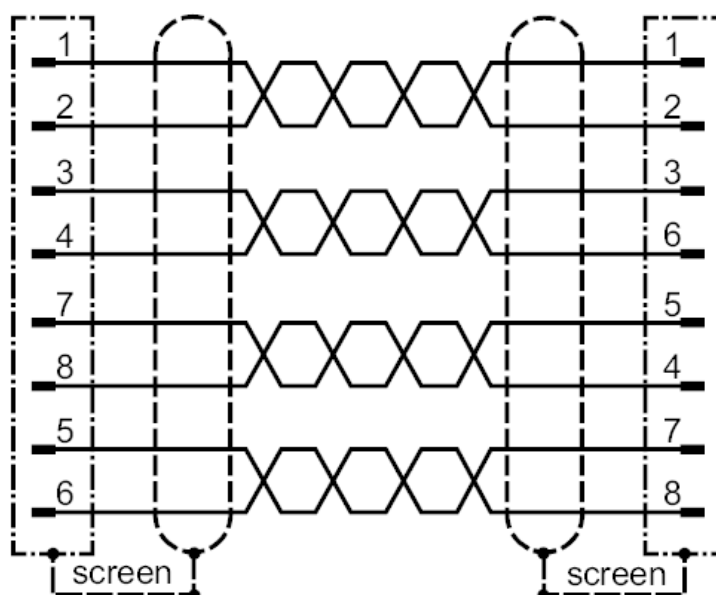

Electrical connection - plug

Connector: 1 x RJ45, straight; Moulded body: PA

