


ZH4117

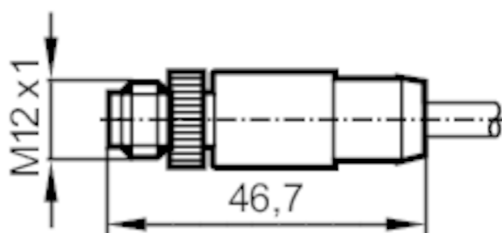

Male cordsets

ASTGH120MSS0003K12



Application

System	gold-plated contacts; screened cable
--------	--------------------------------------

Electrical data

Operating voltage	[V]	< 30 AC/DC
Protection class		II
Max. current load total	[A]	1.5

Operating conditions

Ambient temperature	[°C]	-30...80
Ambient temperature (moving)	[°C]	-5...80
Protection		IP 67

Mechanical data

Weight	[g]	150.8
Dimensions	[mm]	14.5 x 14.5 x 48.5
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

ZH4117



Male cordsets


ASTGH120MSS0003K12

Electrical connection

Cable: 3 m, PUR, black, Ø 6.5 mm, screened; 12 x 0.14 mm² (18 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU (urethane); Locking: zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.4 Nm

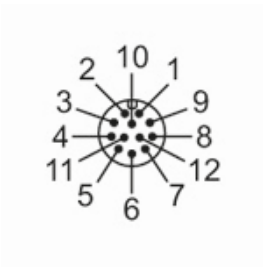

Connection