


ZJ4011

 


Wirable plug

SSTGF040ZDSFPKG

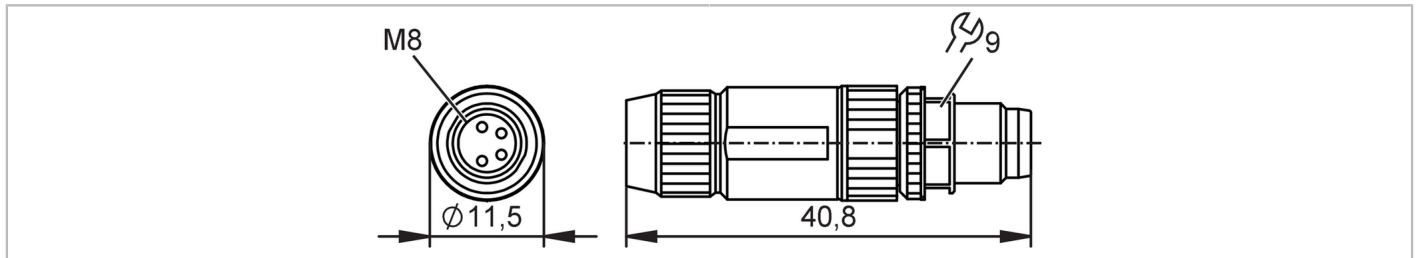

Application	
Special feature	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 32 AC/DC
Protection class	III
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 67
Mechanical data	
Weight [g]	13.6
Dimensions [mm]	12 x 12 x 35.5
Material	PA
Molded-body material	PA
Material nut	diecast zinc
Accessories	
Items supplied	sealing: 2,5...3,2 mm/3,2...4 mm/4...5,1 mm
Remarks	
Pack quantity	1 pcs.
Electrical connection	
insulation displacement technology: 0.14...0.34 mm ² ; Core insulation: PVC/PP/TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 2.5...5.1 mm	
Electrical connection - plug	
Connector: 1 x M8, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: diecast zinc	



ZJ4011

Wirable plug

SSTGF040ZDSFPKG



Connection

