


# ZJ4012



## Female wirable connectors

SDOGF040ZDSFPGK

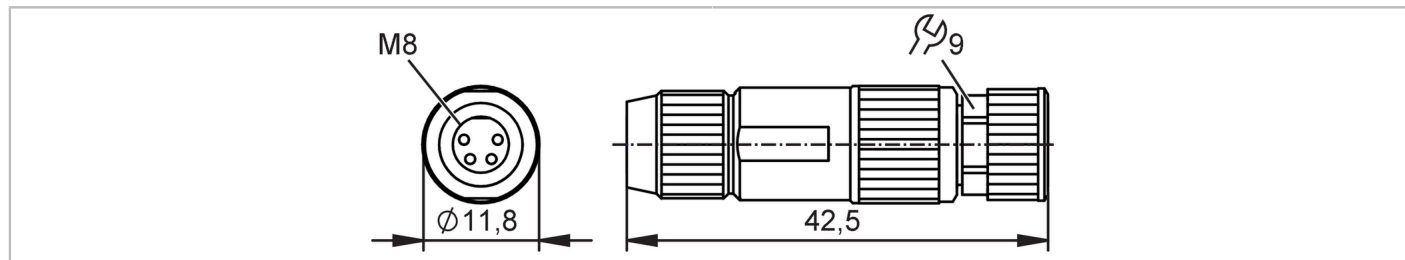

### Application

Special feature	gold-plated contacts
Application	Industrial applications

### Electrical data

Operating voltage [V]	< 32 AC/DC
Protection class	III
Max. current load total [A]	4

### Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 67

### Mechanical data

Weight [g]	14.6
Material	PA
Molded-body material	PA
Material nut	diecast zinc

### Accessories

Items supplied	sealing: 2,5...3,2 mm/3,2...4 mm/4...5,1 mm
----------------	---

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

insulation displacement technology: 0.14...0.34 mm<sup>2</sup>; Core insulation: PVC/PP/TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 2.5...5.1 mm

### Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: diecast zinc



### Connection

