


ZJ4012



Female wirable connectors

SDOGF040ZDSFPKG

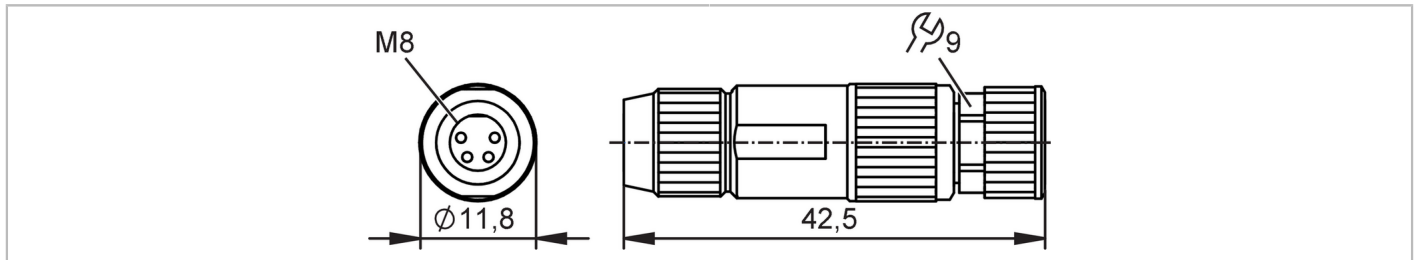

Application

Special feature	gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 32 AC/DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Weight	[g]	14.6
Material		PA
Molded-body material		PA
Material nut		diecast zinc

Accessories

Items supplied	sealing: 2,5...3,2 mm/3,2...4 mm/4...5,1 mm
----------------	---

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

insulation displacement technology: 0.14...0.34 mm²; Core insulation: PVC/PP/TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 2.5...5.1 mm

Electrical connection - Socket

 Connector: 1 x M8, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: diecast zinc



ZJ4012



Female wirable connectors

SDOGF040ZDSFPKG

Connection

