


## Lower part for AS-Interface module

EEMS-Base FC V2A

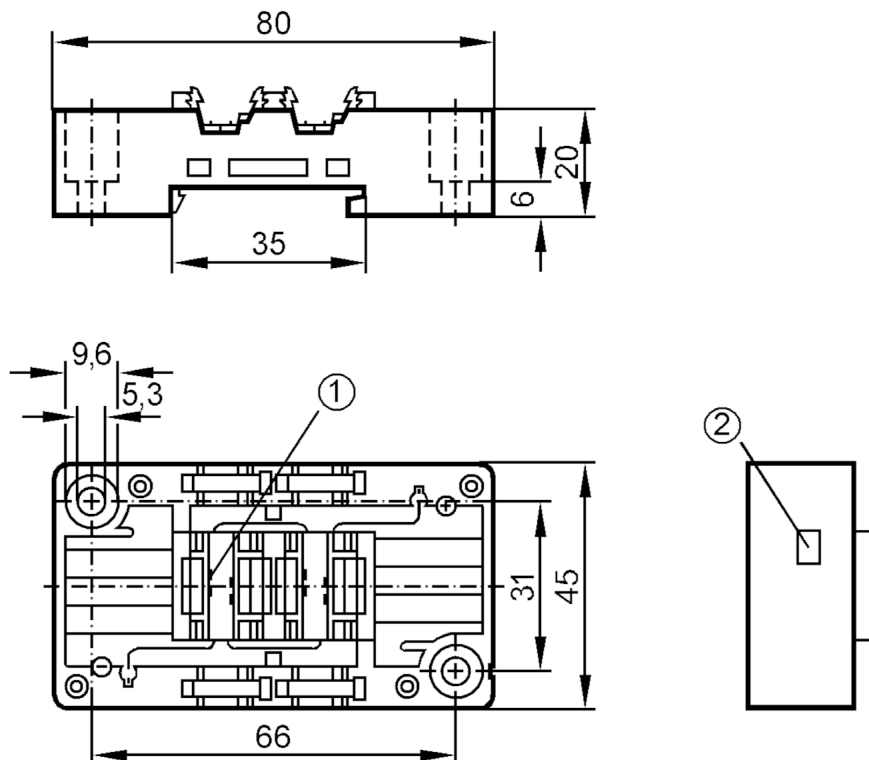

- 1 contact pins  
2 panel for labelling

## Electrical data

|                           |     |                |
|---------------------------|-----|----------------|
| Operating voltage         | [V] | 26.5...31.6 DC |
| Additional voltage supply | [V] | 24 DC          |

## Outputs

|                   |       |
|-------------------|-------|
| Electrical design | AS-i  |
| Contact rating    | < 2 A |

## Operating conditions

|                     |                                                                  |          |
|---------------------|------------------------------------------------------------------|----------|
| Ambient temperature | [°C]                                                             | -25...85 |
| Protection          | IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67) |          |

## Mechanical data

|                  |                                   |              |
|------------------|-----------------------------------|--------------|
| Weight           | [g]                               | 61           |
| Type of mounting | mounting on DIN rail and panel    |              |
| Dimensions       | [mm]                              | 45 x 80 x 20 |
| Materials        | PBT; stainless steel (303/1.4305) |              |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

## Electrical connection

contact pins in module upper part :  
quick mounting technology for AS-i flat cable: