

E10715




Wirable plug

SSTA050MSSFKPG

Article no longer available - archive entry

Alternative articles: E11507
When selecting an alternative article and accessories please note that technical data may differ!

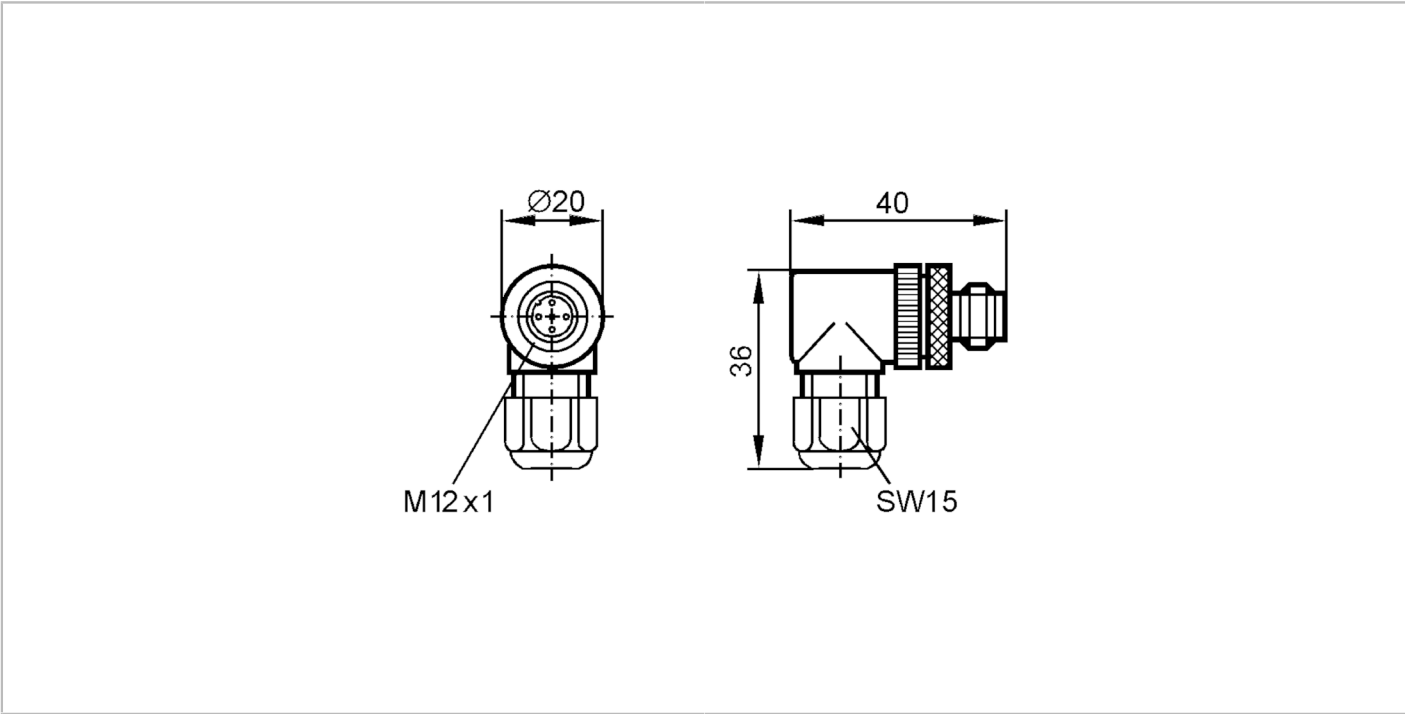

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Dimensions	[mm]	40 x 20 x 36
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10715



Wirable plug


SSTA050MSSFKPG

Electrical connection

terminals:

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated

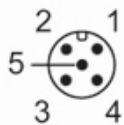

Connection

