


E10788



Wirable plug

SSTAA030MSSFKPG

Article no longer available - archive entry

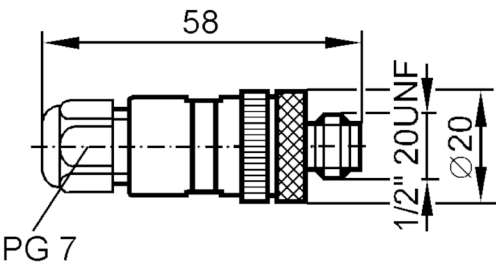

Electrical data

Operating voltage	[V]	< 250 AC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	25
Dimensions	[mm]	20 x 20 x 58
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 7

Electrical connection - plug

Connector: 1 x 1/2", straight; coding: C; Moulded body: PA; Locking: brass, nickel-plated



E10788

Wirable plug

SSTAA030MSSFKPG



Connection

