


# E10290



## Splitter box

ZDO4H045MSS0,03A07

Article no longer available - archive entry

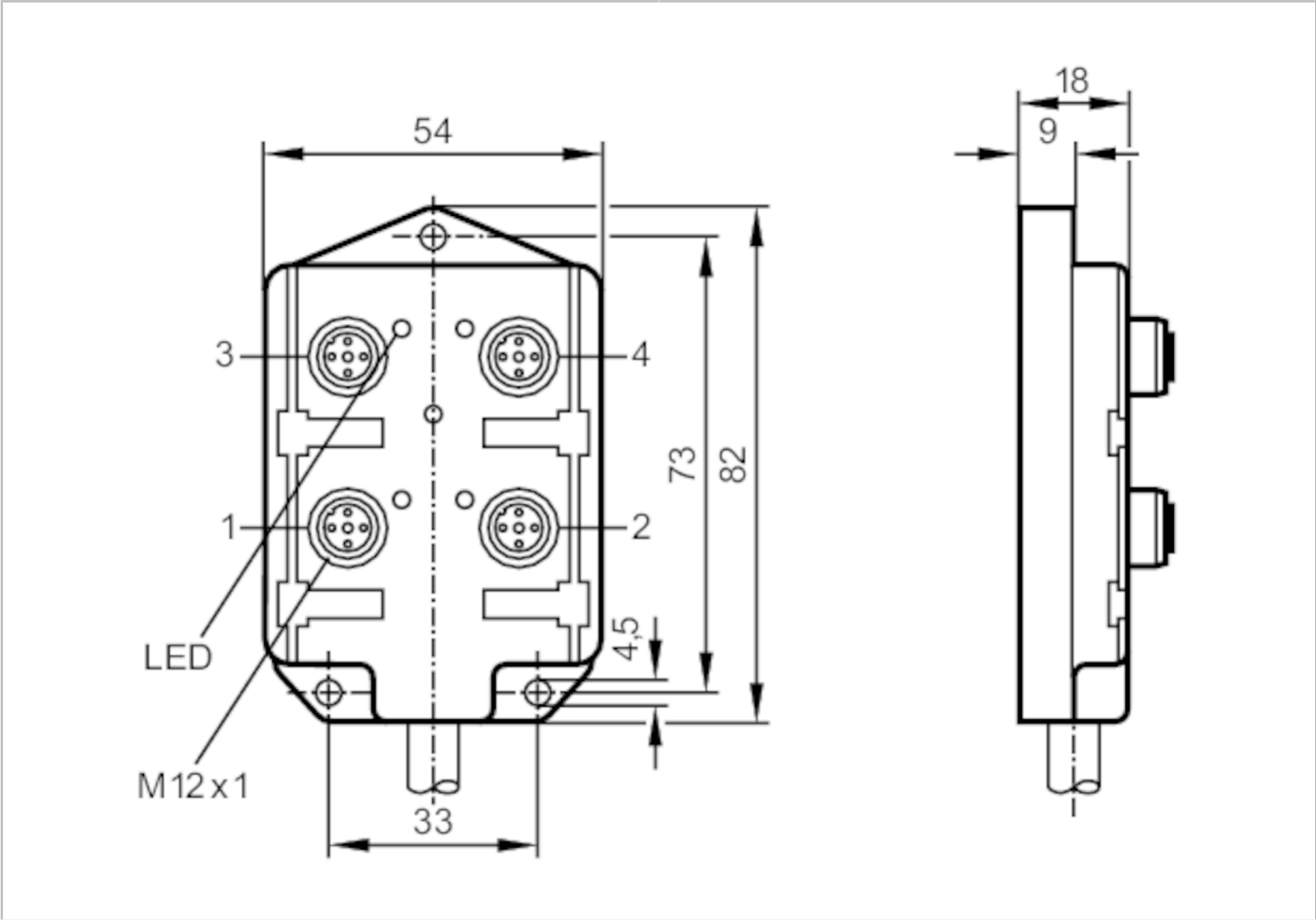

| Electrical data                   |                  |                 |
|-----------------------------------|------------------|-----------------|
| Operating voltage                 | [V]              | 10...30 DC      |
| Max. current load per module/slot | [A]              | 4               |
| Max. current load total           | [A]              | 12              |
| Operating conditions              |                  |                 |
| Ambient temperature               | [°C]             | -15...90        |
| Protection                        |                  | IP 67           |
| Mechanical data                   |                  |                 |
| Dimensions                        | [mm]             | 18 x 54 x 82    |
| Number of ports splitter box      |                  | 4               |
| Displays / operating elements     |                  |                 |
| Display                           | switching status | 4 x LED, yellow |
|                                   | operation        | 1 x LED, green  |
| Remarks                           |                  |                 |
| Pack quantity                     |                  | 1 pcs.          |

# E10290



## Splitter box


ZDO4H045MSS0,03A07

### Electrical connection

Cable: 0.35 m, PUR / PVC; 4 x 0.34 mm<sup>2</sup> + 3 x 0.75 mm<sup>2</sup>

### Electrical connection - slot

Connector: 4 x M12; coding: A; Tightening torque: 0.5 Nm

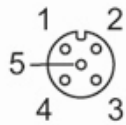

### Connection

|       |           |   |
|-------|-----------|---|
| BN    | 1 (1...4) | C |
| BU    | 3 (1...4) | C |
| GN/YE | 5 (1...4) | C |
| WH    | 4 (1)     | C |
| GN    | 4 (2)     | C |
| YE    | 4 (3)     | C |
| GY    | 4 (4)     | C |

|         |                |
|---------|----------------|
|         | Core colours : |
| BN =    | brown          |
| BU =    | blue           |
| GN =    | green          |
| GN/YE = | green/yellow   |
| GY =    | grey           |
| WH =    | white          |
| YE =    | yellow         |