




Connecting cable with socket

ADOAH040MSS0005F03

Article no longer available - archive entry

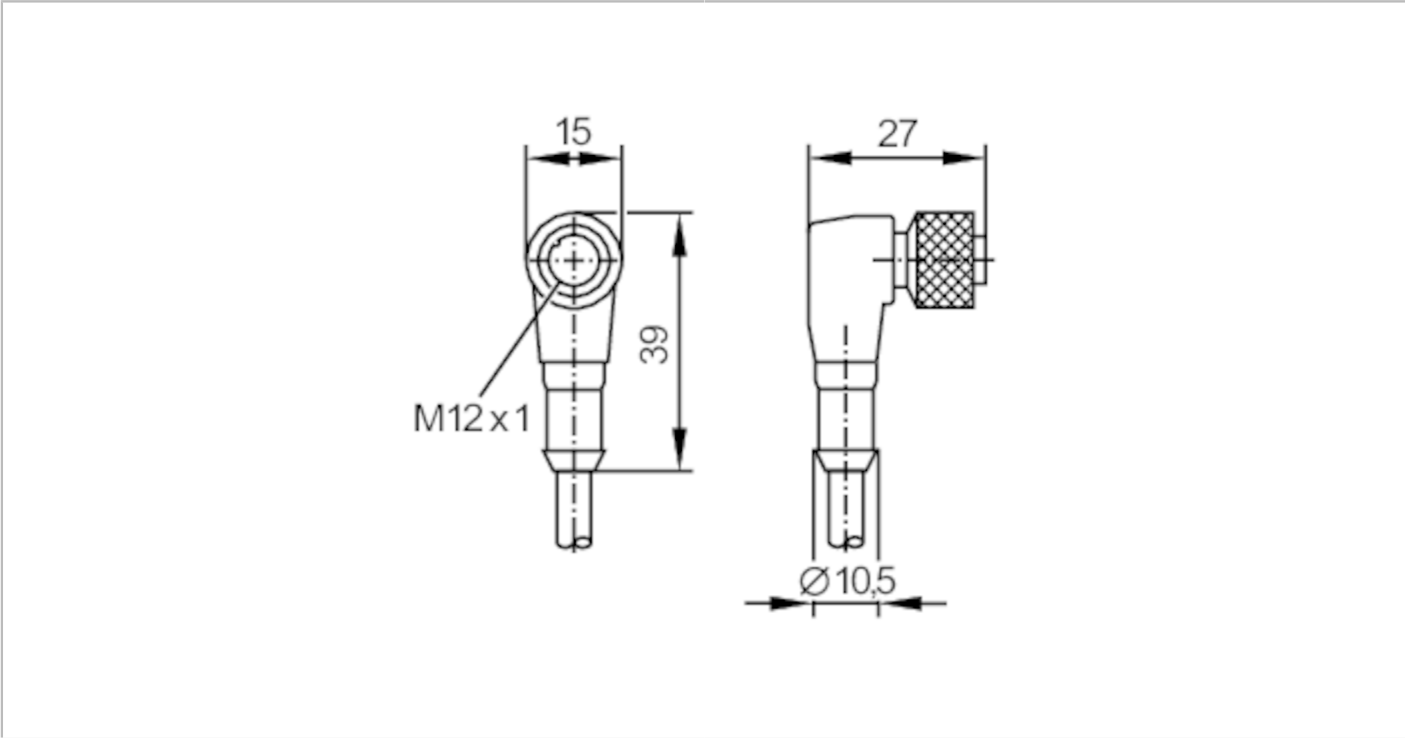

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		brass, anti-spatter
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm²		
Electrical connection - socket		

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, anti-spatter; Tightening torque: 0.5 Nm




E10296



Connecting cable with socket

ADOAH040MSS0005F03

Connection

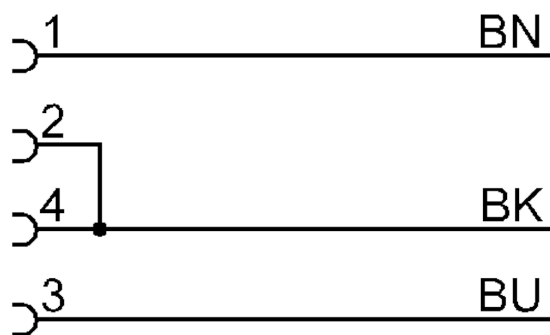

BN =
BK =
BU =

Core colours :
brown
black
blue