


E11065



Connection cable

VDOAH043MSS01,5H04STAH040MSS

Article no longer available - archive entry

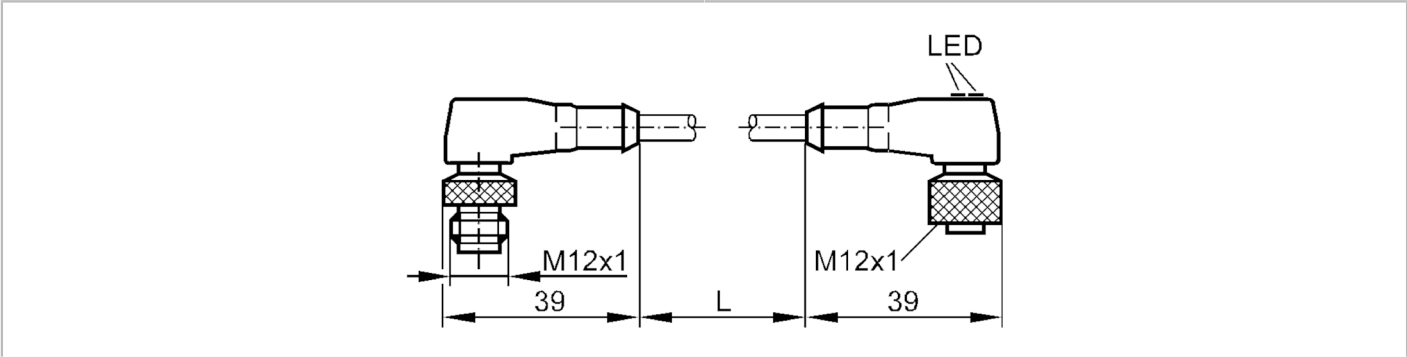

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	switching status	2 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 1.5 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Electrical connection - plug



E11065




Connection cable

VDOAH043MSS01,5H04STAH040MSS

Electrical connection

Connection

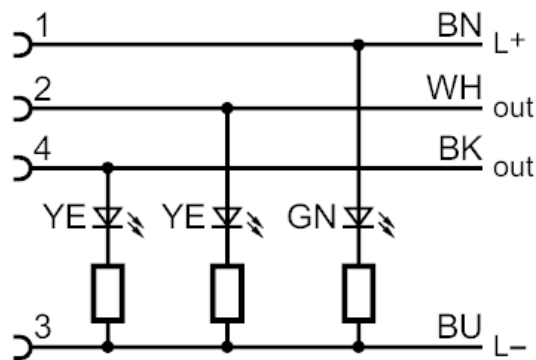

Core colours :
BK = black
BN = brown
BU = blue
WH = white

Electrical connection - socket



Electrical connection - plug

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated

Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated