




Connection cable

VDOAF032MSS00,3H03STGF030MSS

Article no longer available - archive entry

Alternative articles: EVC280  
When selecting an alternative article and accessories please note that technical data may differ!

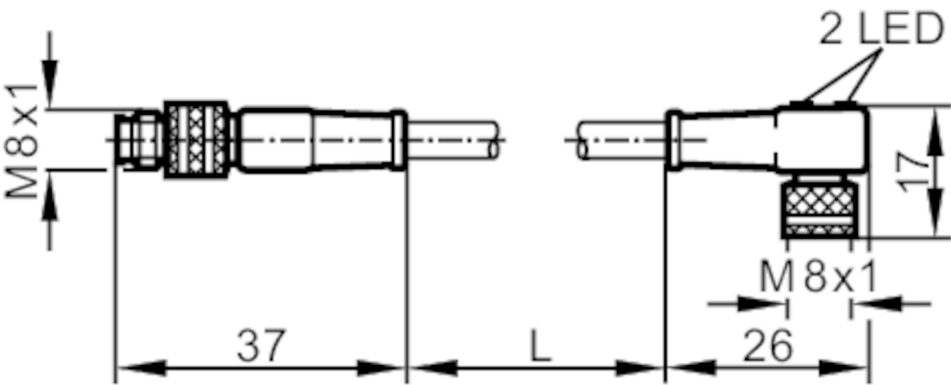

| Application                   |                                                        |                 |
|-------------------------------|--------------------------------------------------------|-----------------|
| Special feature               | Free from silicone; Halogen-free; Gold-plated contacts |                 |
| Free from silicone            | yes                                                    |                 |
| Electrical data               |                                                        |                 |
| Operating voltage             | [V]                                                    | 10...30 DC      |
| Protection class              |                                                        | III             |
| Max. current load total       | [A]                                                    | 3               |
| Outputs                       |                                                        |                 |
| Electrical design             | PNP                                                    |                 |
| Operating conditions          |                                                        |                 |
| Ambient temperature           | [°C]                                                   | -25...85        |
| Protection                    |                                                        | IP 68           |
| Mechanical data               |                                                        |                 |
| Materials                     | PUR                                                    |                 |
| Moulded-body material         | PUR                                                    |                 |
| Material nut                  | brass, nickel-plated                                   |                 |
| Displays / operating elements |                                                        |                 |
| Display                       | switching status                                       | 1 x LED, yellow |
|                               | operation                                              | 1 x LED, green  |



## Connection cable

VDOAF032MSS00,3H03STGF030MSS

### Remarks

Pack quantity

1 pcs.

### Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection



### Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

