


# E12315



## Terminating resistor for PROFIBUS DP

ProfiBus Terminat. Resistor

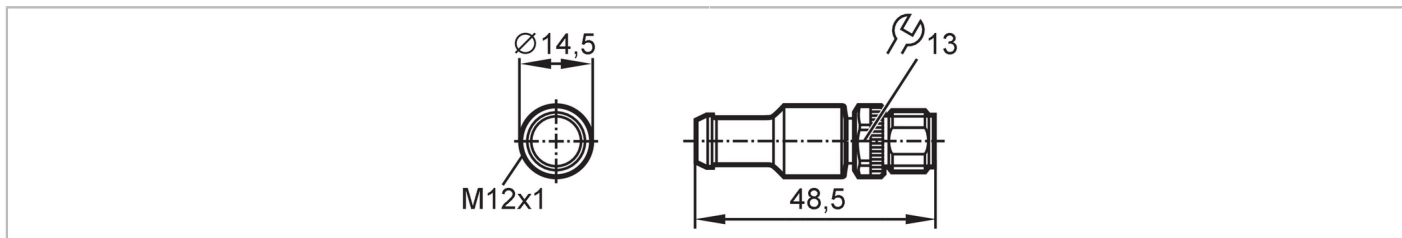

Application	
Special feature	Free from silicone; Gold-plated contacts
Application	Industrial applications / factory automation
Free from silicone	yes

Electrical data	
Max. current load total [A]	4; (...40 °C)

Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 67

Mechanical data	
Weight [g]	9.9
Dimensions [mm]	14.5 x 14.5 x 48.5
Moulded-body material	PUR
Material nut	brass, nickel-plated

Remarks	
Pack quantity	1 pcs.

### Electrical connection - plug

Connector: 1 x M12, straight; coding: B; Contacts: 4, gold-plated; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.6 Nm



### Connection

