



Connecting cable with socket

ADOGH040MSS0005G04

No scale drawing available

Application

Special feature	Screened cable
-----------------	----------------

Electrical data

Operating voltage	[V]	< 250 DC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-40...90
---------------------	------	----------

Protection	IP 68
------------	-------

Mechanical data

Weight	[g]	254.012
--------	-----	---------

Materials	PUR
-----------	-----

Moulded-body material	PUR
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC, yellow, Ø 5.6 mm, shielded; 4 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm




E18025



Connecting cable with socket

ADOGH040MSS0005G04

Connection

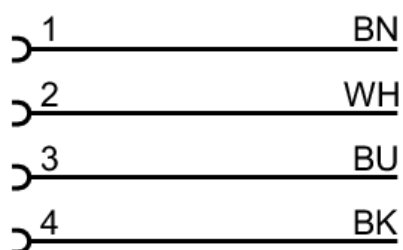

BN =	Core colours :	brown
BK =		black
BU =		blue
WH =		white