




Wirable plug

SSTGH040VASFKPG7

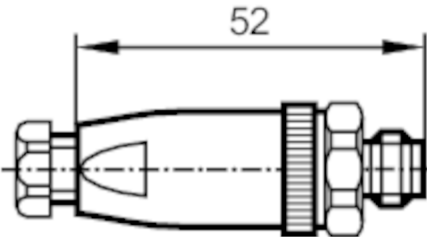

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 68

Mechanical data

Weight	[g]	22.7
Dimensions	[mm]	20 x 20 x 52
Materials		PA
Moulded-body material		PA
Material nut		stainless steel (316Ti/1.4571)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: stainless steel (316Ti/1.4571); Contacts: pre-coppered brass



E18163

Wirable plug

SSTGH040VASFKPG7



Connection

