


E18208



Connecting cable with socket

ADOGA030VAS0025E03

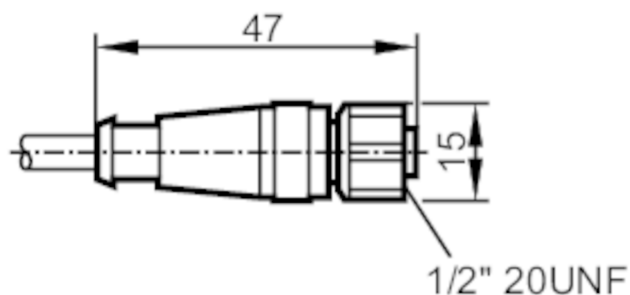

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-10...100
Protection		IP 68

Mechanical data

Weight	[g]	874.979
Dimensions	[mm]	15 x 15 x 47
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316Ti/1.4571)

Remarks

Pack quantity	1 pcs.
---------------	--------

E18208



Connecting cable with socket

ADOGA030VAS0025E03

Electrical connection


Cable: 25 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



Connection

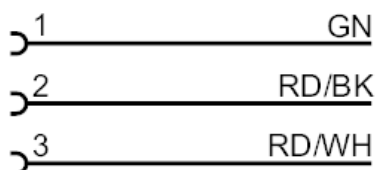

GN =	Core colours :
RD/BK =	green
RD/WH =	red/black
	red/white