


## Fibre optic diffuse reflection sensor

FT-00-M-V-M6/2,5m

Article no longer available - archive entry

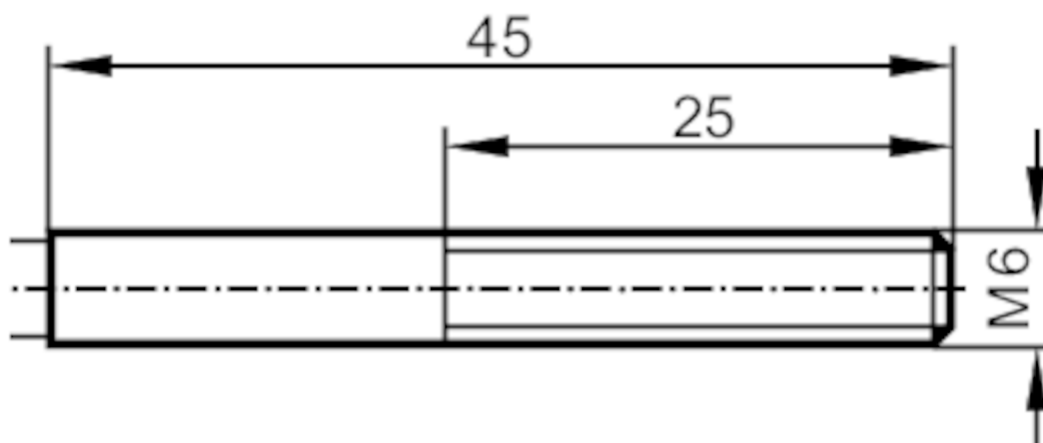

## Application

Function principle

Diffuse reflection sensor

## Detection zone

Range with fibre optic amplifier type

OKF; OUF

## OKF

Range fibre optics

[mm]

28

## OUF

Range fibre optics

[mm]

28

## Operating conditions

Ambient temperature

[°C]

-20...150

## Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

45

Total length

[mm]

2500

Min. bending radius

[mm]

20

Fibre material

glass

Fibre head material

stainless steel (303/1.4305)

E20525



Fibre optic diffuse reflection sensor

FT-00-M-V-M6/2,5m

|                       |                |
|-----------------------|----------------|
| Fibre sheath material | metal silicone |
| Remarks               |                |
| Pack quantity         | 1 pcs.         |