


Fibre optic diffuse reflection sensor

FT-00-P-A-M4

Article no longer available - archive entry

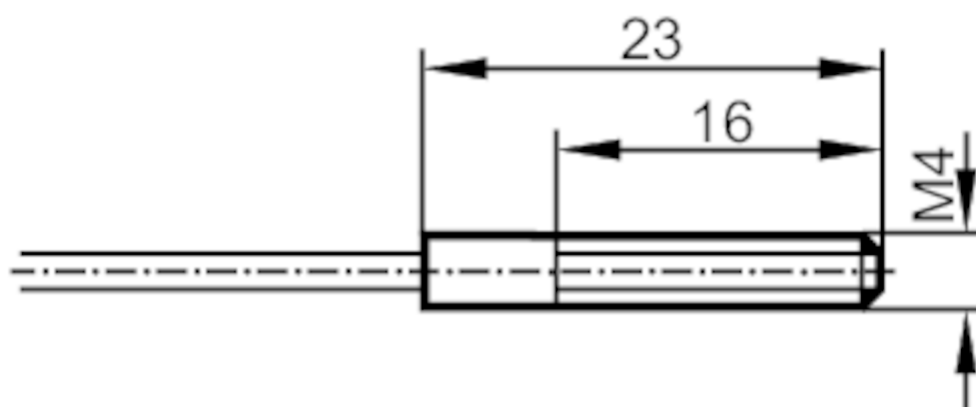

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics [mm]	20
-------------------------	----

OUF

Range fibre optics [mm]	20
-------------------------	----

Operating conditions

Ambient temperature [°C]	-20...80
--------------------------	----------

Mechanical data

Version of sensing head	straight
-------------------------	----------

Sensing head thread	M4
---------------------	----

Total length [mm]	600
-------------------	-----

Min. bending radius [mm]	20
--------------------------	----

Materials	Adapter: ABS
-----------	--------------

Fibre material	glass
----------------	-------

Fibre head material	aluminium
---------------------	-----------

E20835



Fibre optic diffuse reflection sensor

FT-00-P-A-M4

Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.