




Fibre optic through-beam sensor

FE-30-P-A-R6/0,8m

Article no longer available - archive entry

Alternative articles: E20329
When selecting an alternative article and accessories please note that technical data may differ!

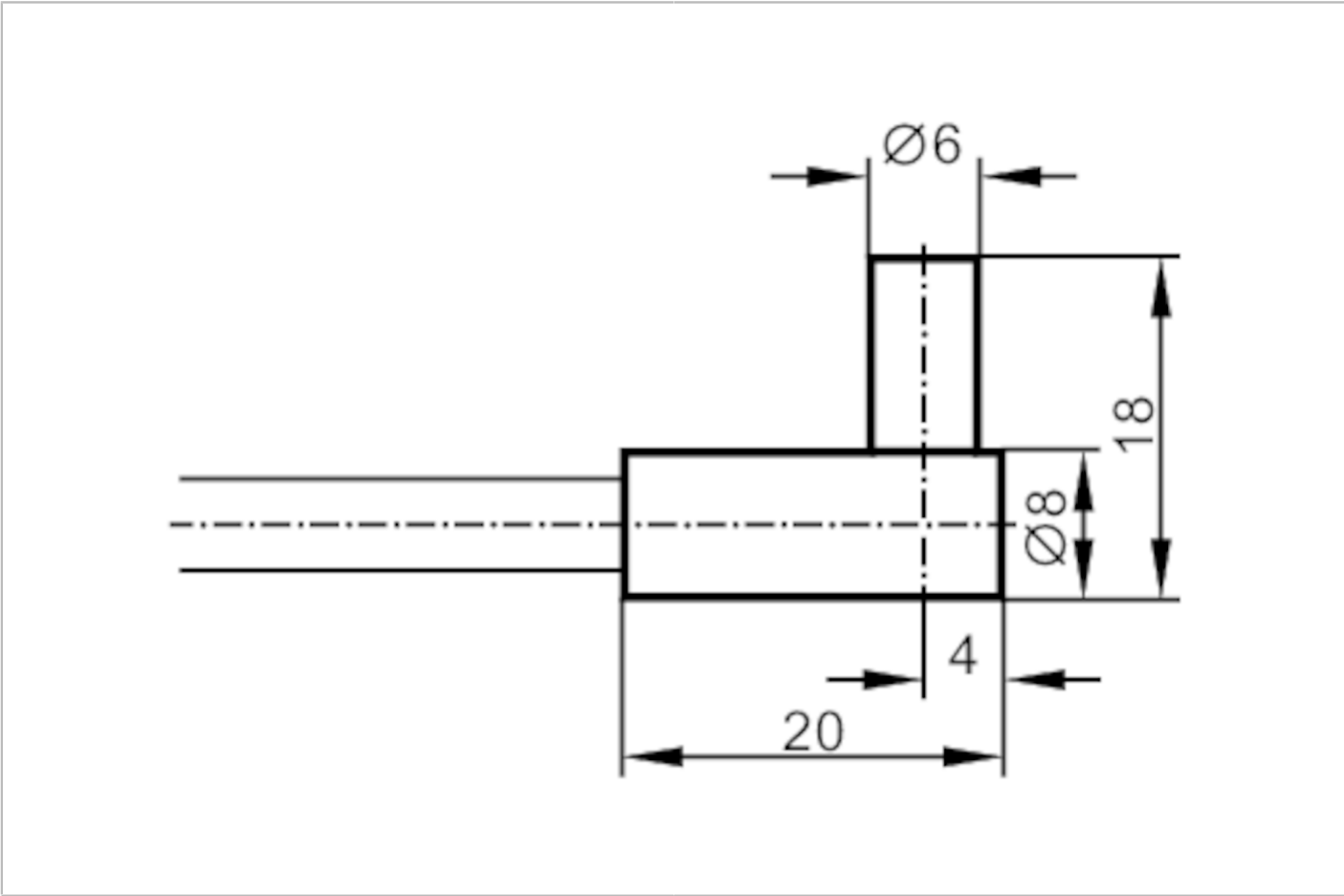

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OIF
OIF	
Range of fibre optics [mm]	300
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	angled
Total length [mm]	800
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC

E20396



Fibre optic through-beam sensor

FE-30-P-A-R6/0,8m

Remarks

Pack quantity	1 pcs.
---------------	--------