


E60128



Wirable plug


SSTGK120MKRFKSG

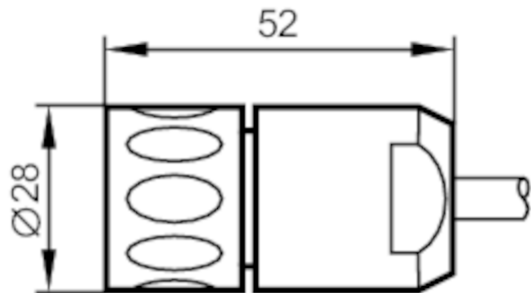

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...125
Protection		IP 67
Mechanical data		
Weight	[g]	45.2
Dimensions	[mm]	28 x 28 x 52
Materials		brass in plastic sheath; PA 6.6 black
Moulded-body material		brass / PA 6.6, in plastic sheath
Material nut		brass, in plastic sheath / PA 6.6, in plastic sheath
Remarks		
Pack quantity		1 pcs.

Electrical connection	
soldering: ...1 mm ²	

Electrical connection - plug	
Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath	
Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath	

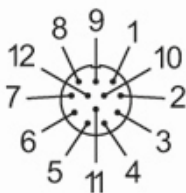

E60128



Wirable plug

SSTGK120MKRFKSG

Connection

