


E70136



Jumper cable with valve plug

VVDAC041--S0001A03STGH030MSS

Article no longer available - archive entry

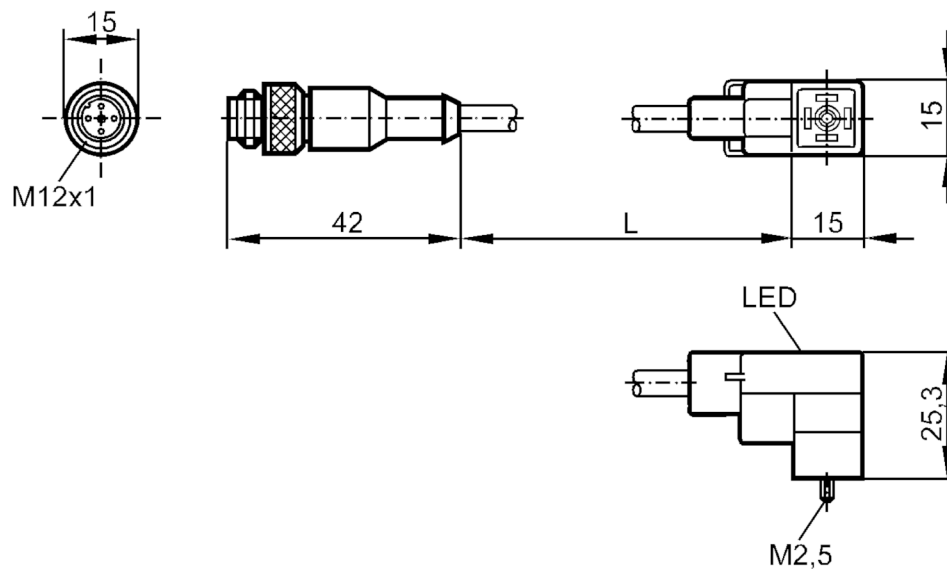

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Displays / operating elements

Display	operation	1 x LED, yellow
---------	-----------	-----------------

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E70136




Jumper cable with valve plug

VVDAC041--S0001A03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 1 m, PUR / PVC; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Connection

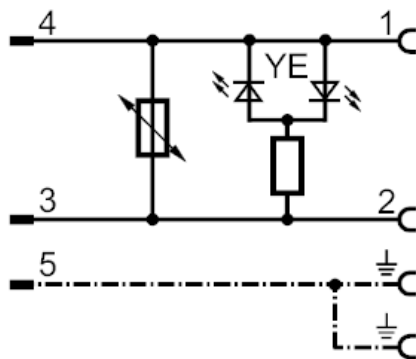

Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

