




Splitter box

ZDO4F035MSJ0000---STGH080MSJ

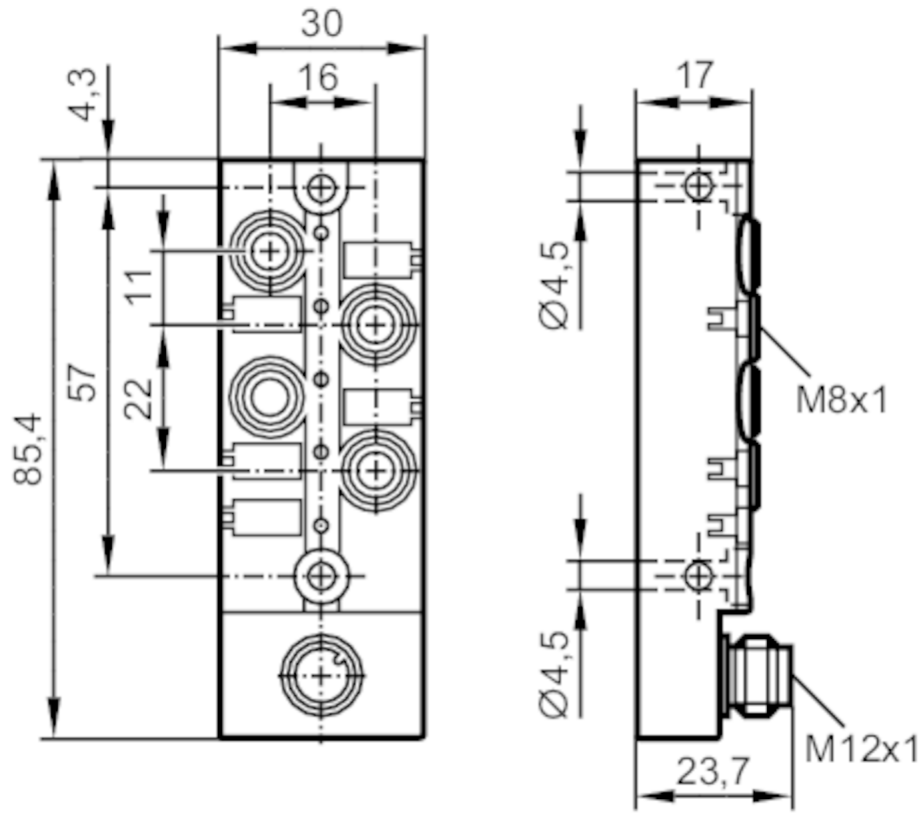

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	10...30 DC; ("supply class 2" to cULus)
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	2

Outputs

Electrical design	NPN
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...80
Ambient temperature (moving)	[°C]	-5...60
Protection		IP 65; IP 67; IP 68; (1 m / 7 days)

Mechanical data

Weight	[g]	88
Dimensions	[mm]	23.7 x 30 x 85.4
Materials		PBT-GF20; brass nickel-plated
Moulded-body material		PBT-GF 20 / brass, nickel-plated
Number of ports splitter box		4



Splitter box

ZDO4F035MSJ0000---STGH080MSJ

Connector type	M8
----------------	----

Displays / operating elements

Display	switching status	4 x LED, yellow
	operation	1 x LED, green

Accessories


Accessories (optional)	DIN rail adapter:., E73006
	Protective cap: M8, E73005

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

Connector: 1 x M12; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

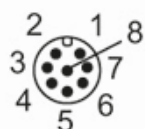

Connection

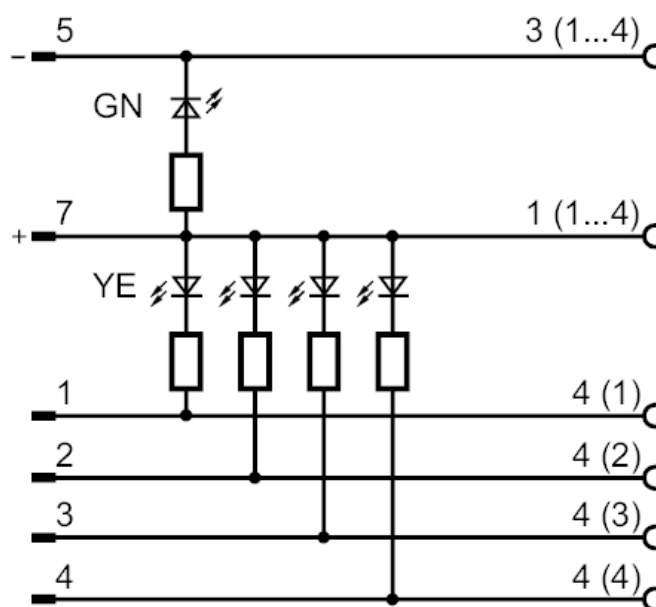

EBC060



Splitter box

ZDO4F035MSJ0000---STGH080MSJ

Electrical connection - slot

Connector: 4 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

