


AC1146



AS-Interface diagnosis module

AS-i Tuner IP67

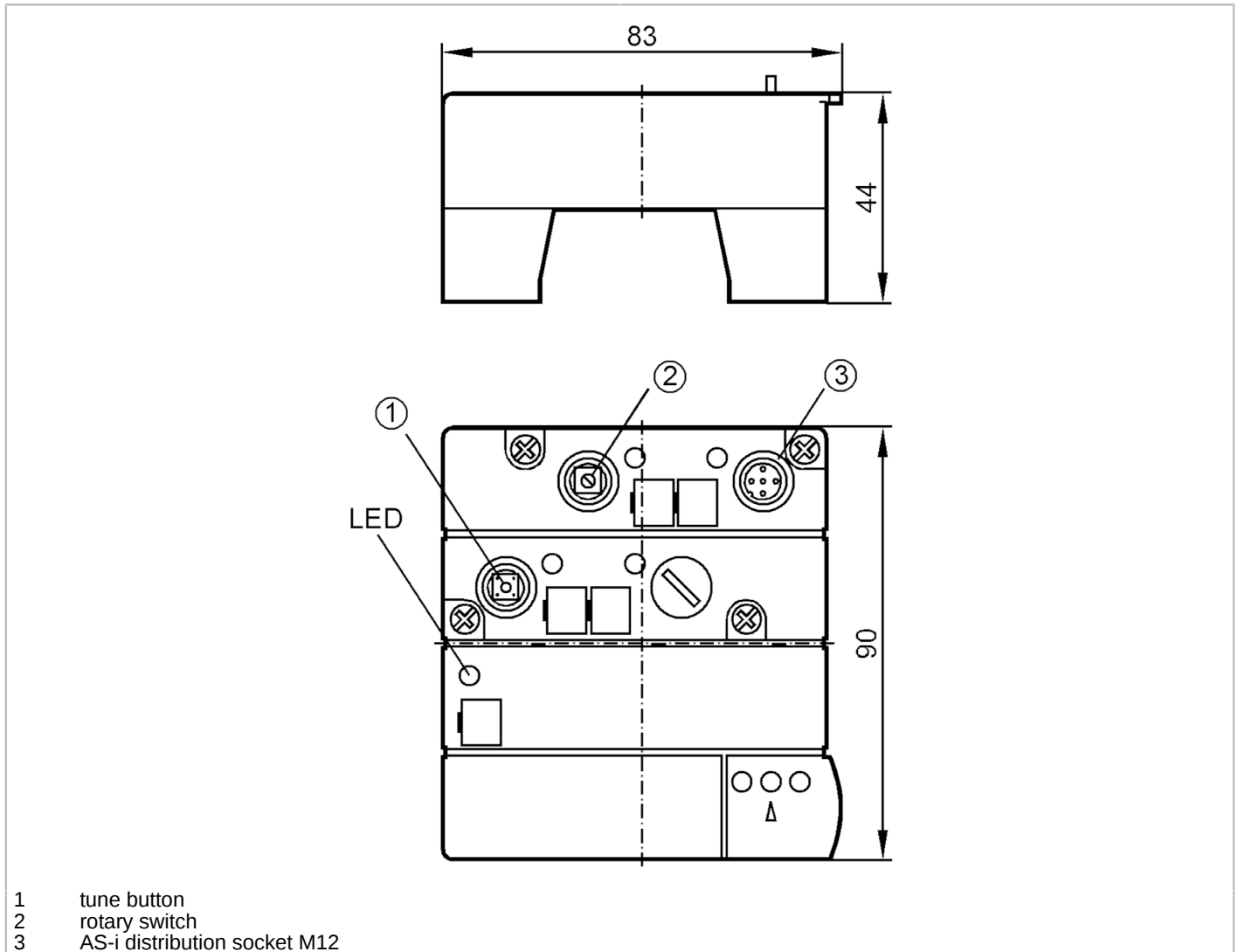

Application	
Application	diagnostic tool for AS-i
Electrical data	
Nominal voltage DC [V]	26.5...31.6
Max. current consumption from AS-i [mA]	60
Reverse polarity protection	yes
Undervoltage monitoring	yes
Operating conditions	
Ambient temperature [°C]	0...55
Protection	IP 67
Tests / approvals	
MTTF [years]	140
Mechanical data	
Weight [g]	199.2

AC1146



AS-Interface diagnosis module

AS-i Tuner IP67

Housing	rectangular
Dimensions [mm]	83 x 90 x 44
Materials	housing: PBT

Displays / operating elements

Display	operation	LED, green
	warning	LED, yellow
	errors	LED, red

Accessories

Accessories (optional)	Module lower part:, AC5000
------------------------	----------------------------

Remarks


Remarks	no addressing required
	current rating of the AS-i distribution socket max. 1 A

Pack quantity	1 pcs.
---------------	--------

Electrical connection

contact pins to module lower part, FK:

 Connector: M12; coding: A



	AS-i distribution socket M12
1	AS-i +
3	AS-i -