

AC1213




AS-Interface power supply

AS-i ltd.Power Source Class2

Article no longer available - archive entry

Alternative article: AC1256 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

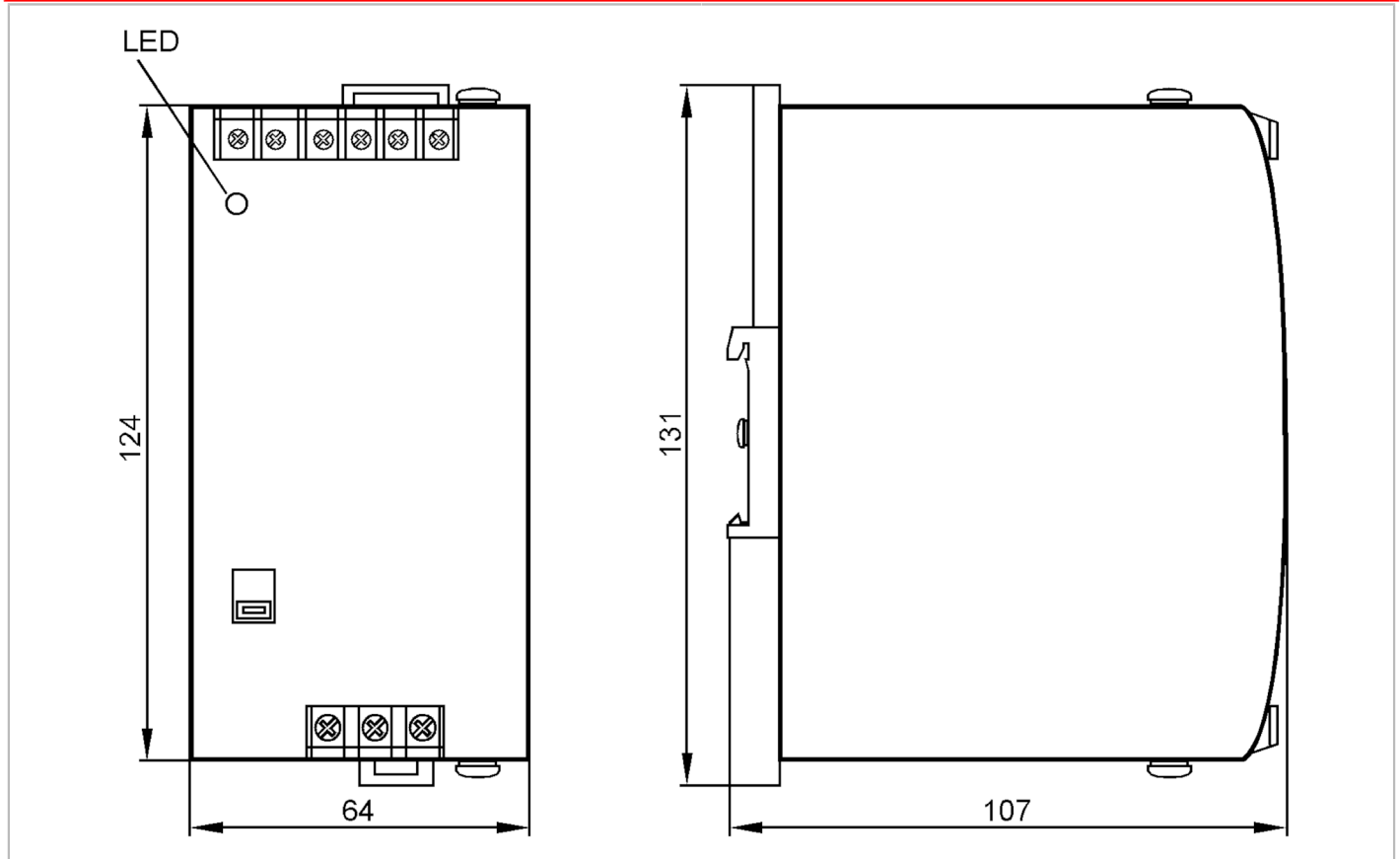

Electrical data		
Nominal voltage AC	[V]	< 230
Nominal frequency AC	[Hz]	47...63
Input voltage AC	[V]	85...132 / 184...264
Output voltage DC	[V]	29.5...31.6
Protection class		I
Max. output current at min. output voltage	[A]	3.2
Number of output circuits		1
Max. residual ripple	[%]	0.1
Derating	[W/K]	2 (> 60 °C)
Outputs		
Short-circuit protection		yes
Overload protection		yes
Operating conditions		
Ambient temperature	[°C]	0...70
Protection		IP 20

AC1213



AS-Interface power supply

AS-i Ltd.Power Source Class2

Tests / approvals

EMC	EN 60950/A2 1993	
	EN 50081-1	
	EN 61000-6-2	

AS-i classification

AS-i certificate pending	yes
--------------------------	-----

Mechanical data

Materials	aluminium
-----------	-----------

Displays / operating elements

Display	function	LED, green
---------	----------	------------


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: 1.5...6 mm²

Connection

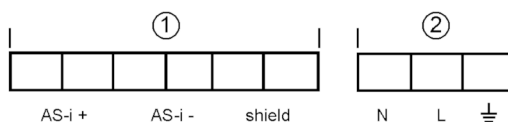

Article no longer available - archive entry

Alternative article: AC1256 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!