


# AC1325



## AS-Interface PROFIBUS DP gateway

ASI DP GATEWAY 1 MASTER

Article no longer available - archive entry

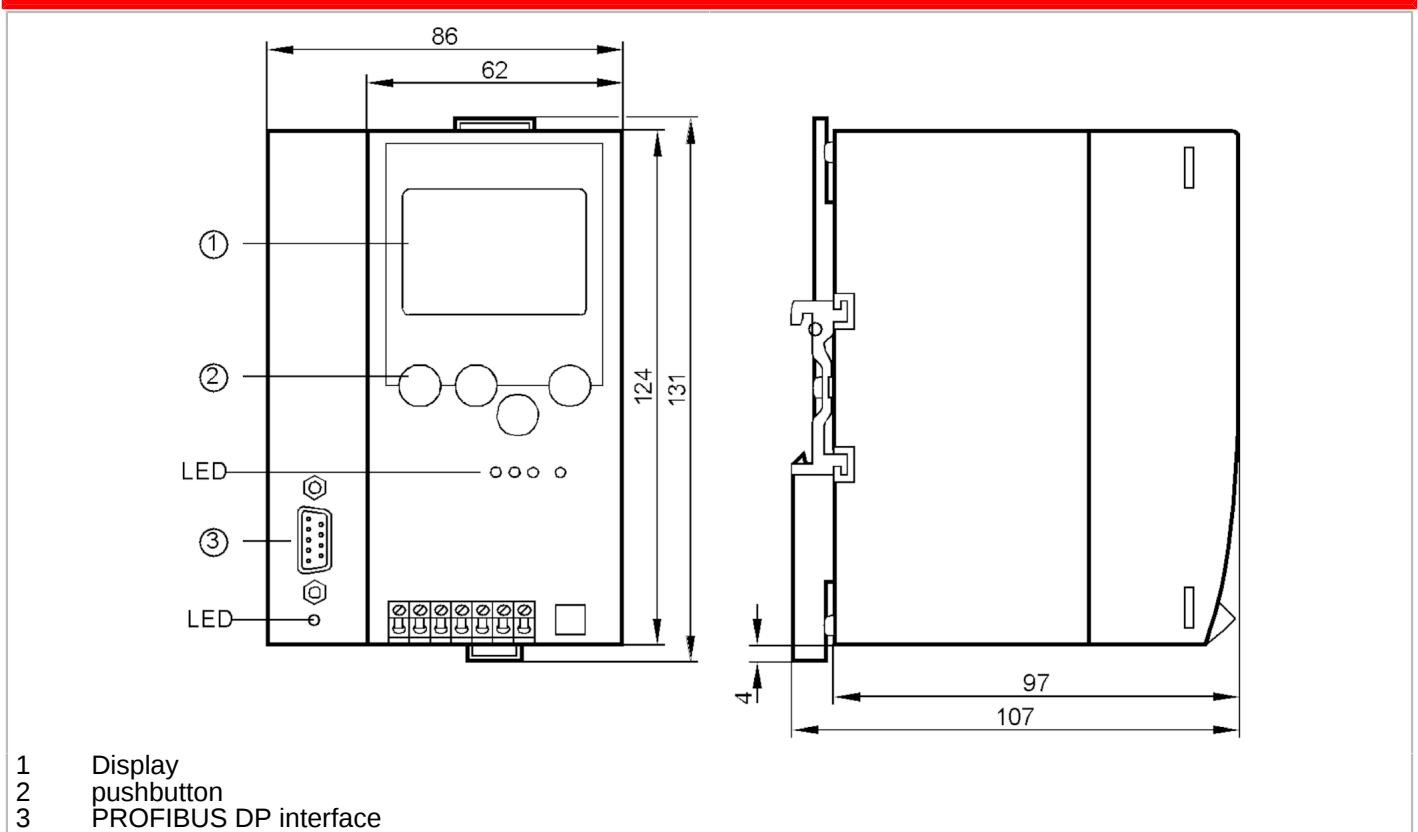

### Application

Application use as Profibus DP gateway with 1 AS-i master

### Electrical data

Operating voltage [V]	24 DC; (operating voltage "supply class 2" according to cULus)
Insulation rating [V]	500
Current consumption [mA]	< 400
Max. current consumption from AS-i [mA]	10
Max. power consumption [VA]	10
Number of AS-i masters	1
Electrical separation	yes

### Interfaces

Communication interface	PROFIBUS
<b>PROFIBUS</b>	
Transmission standard	EN 50170
Transmission rate	12 MBaud
Protocol	Profibus DP
Usage type	data transmission
at_schnittstelle-zusatz	diagnostic function

# AC1325




## AS-Interface PROFIBUS DP gateway

ASI DP GATEWAY 1 MASTER

Operating conditions		
Ambient temperature [°C]	0...60	
Storage temperature [°C]	-20...70	
Max. relative air humidity [%]	95	
Protection	IP 20	
AS-i classification		
AS-i version	2.1	
AS-i profile	M3	
AS-i certificate	61105	
Mechanical data		
Weight [g]	545.6	
Housing	housing for DIN rail mounting	
Materials	aluminium; steel sheet galvanised	
Displays / operating elements		
Display	function	2 x LED, red
		2 x LED, green
		1 x LED, yellow
		full graphic LCD display
Remarks		
Pack quantity	1 pcs.	

### Electrical connection

#### Connection

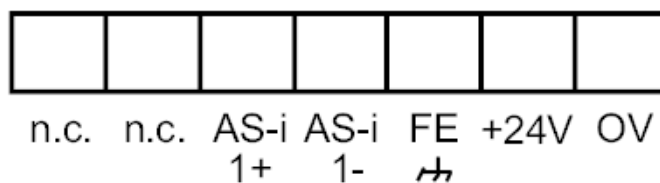

Article no longer available - archive entry