


# E10516



## Connecting cable with socket

ADOAH042MSS0005E03

Article no longer available - archive entry

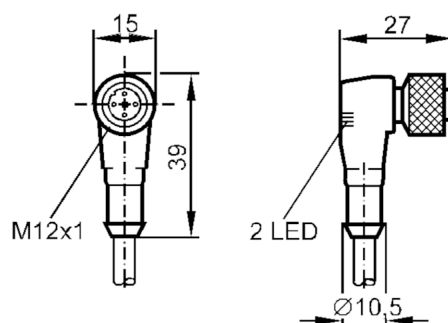

### Electrical data

Operating voltage [V] 10...30 DC

### Outputs

Electrical design PNP

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Materials TPU transparent

Moulded-body material TPU, transparent

Material nut brass, nickel-plated

### Displays / operating elements

|         |                  |                 |
|---------|------------------|-----------------|
| Display | switching status | 1 x LED, yellow |
|         | operation        | 1 x LED, green  |

### Remarks

Pack quantity 1 pcs.

# E10516



## Connecting cable with socket

ADOAH042MSS0005E03

### Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



### Connection

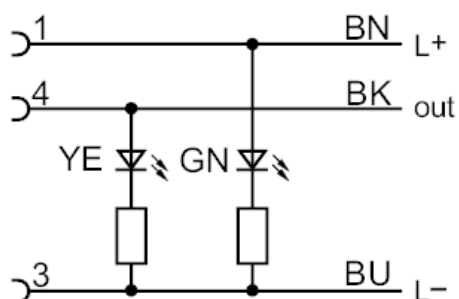

|      |                |
|------|----------------|
| BN = | Core colours : |
| BK = | brown          |
| BU = | black          |
|      | blue           |