

E10562




Connection cable

VDOAH042MSS0001F03STGH040MSS

Article no longer available - archive entry

Alternative articles: E10633
When selecting an alternative article and accessories please note that technical data may differ!

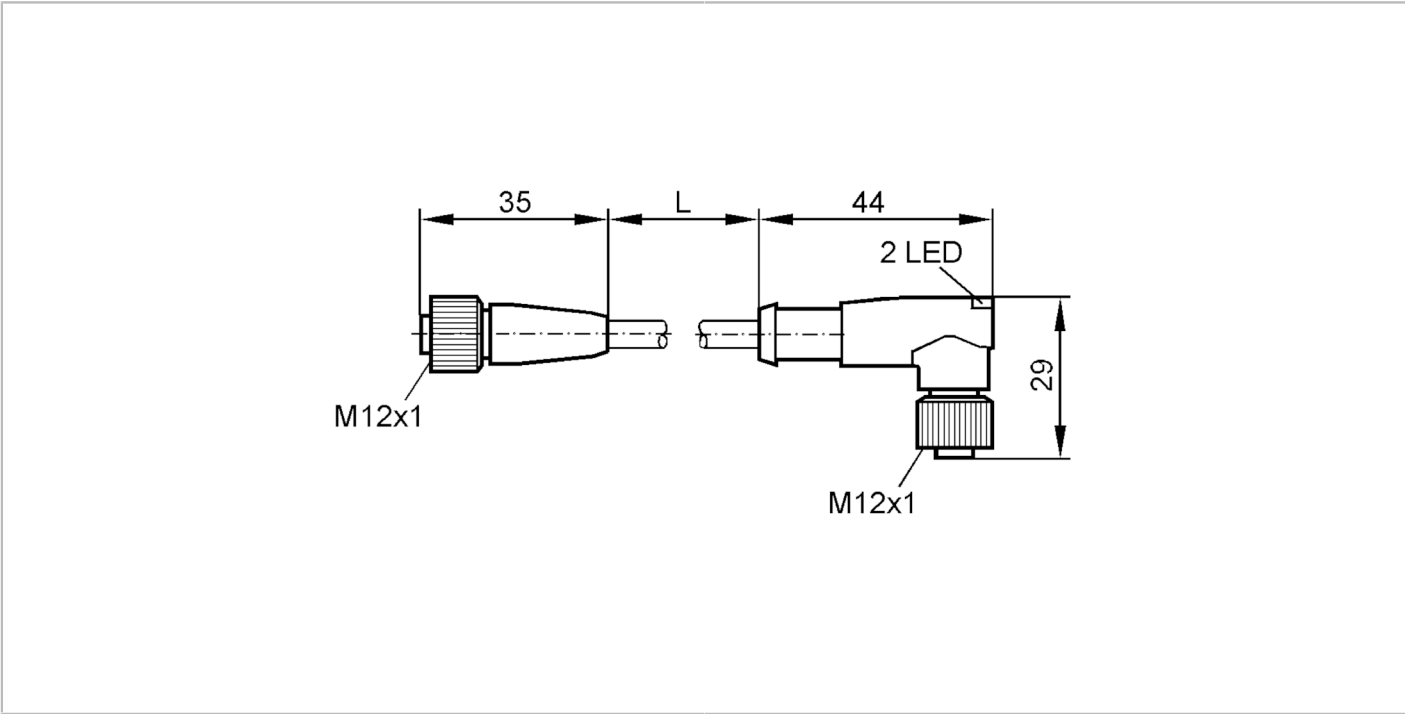

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-20...70
Protection		IP 67
Mechanical data		
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		aluminium, black anodised
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10562



Connection cable

VDOAH042MSS0001F03STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised



Electrical connection

Cable: 1 m, PVC, orange; cross-linked; 3 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised

