




Connection cable

VDOAF030MSS00,6A03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11325

When selecting an alternative article and accessories please note that technical data may differ!

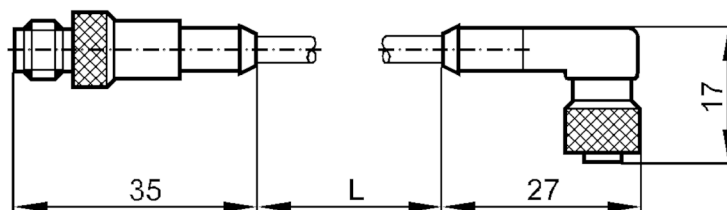

Electrical data

Operating voltage [V] < 60 AC/DC

Protection class III

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 68

Mechanical data

Materials PUR

Moulded-body material PUR

Material nut diecast zinc, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



E10600




Connection cable

VDOAF030MSS00,6A03STGF030MSS

Electrical connection

Cable: 0.6 m, PUR / PVC; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Connection

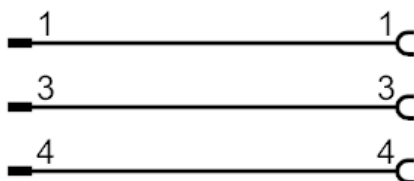

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

