


Jumper cable with valve plug

VVSAC040MSS0003B03STGH040MSS

Article no longer available - archive entry

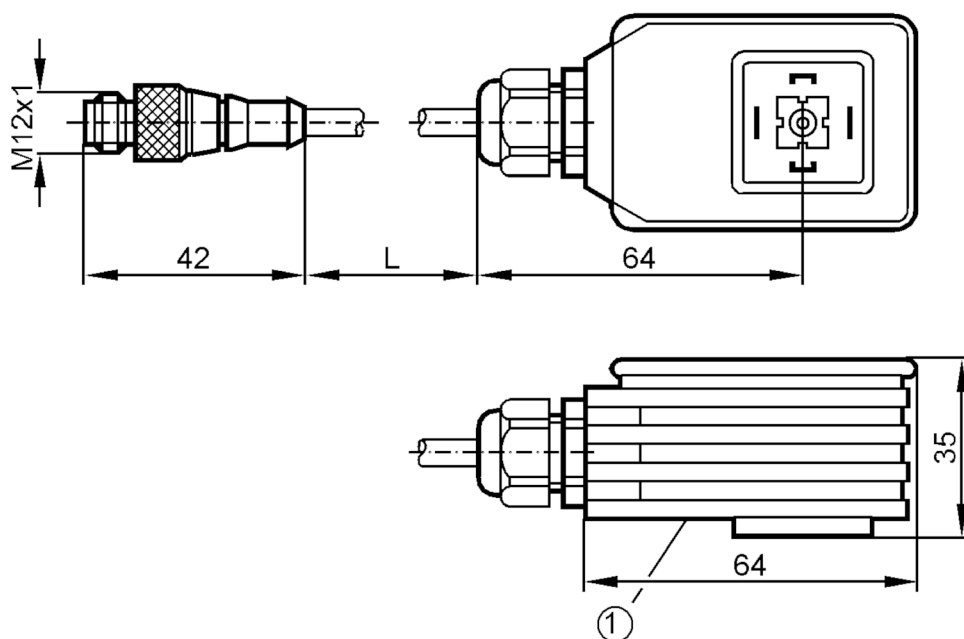

1 black

Application

Design with amplifier

Electrical data

Operating voltage [V] 12...40 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 65

Mechanical data

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10677




Jumper cable with valve plug

VVSAC040MSS0003B03STGH040MSS

Electrical connection

Cable: 3 m, PUR; 3 x 0.5 mm²

Connection

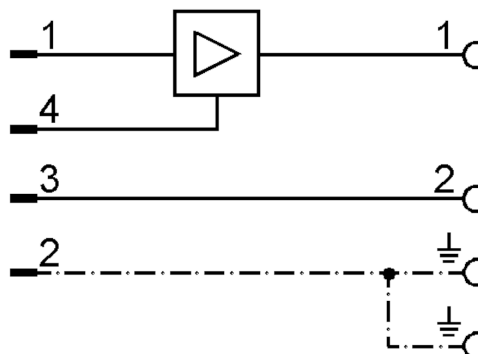

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

