

E10817



Jumper cable with valve plug

VVDAA041--S00,3A03STAH030VAS



Application		
Special feature		Halogen-free
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Oversvoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Weight	[g]	62.55
Dimensions	[mm]	30 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		stainless steel (316L/1.4404)
Displays / operating elements		
Display	operation	1 x LED, yellow

E10817




Jumper cable with valve plug


VVDAA041--S00,3A03STAH030VAS

Accessories	
Items supplied	screw panel for labelling
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	

 Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: stainless steel (316L/1.4404)



Electrical connection
Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm ² (16 x Ø 0.2 mm)
Connection

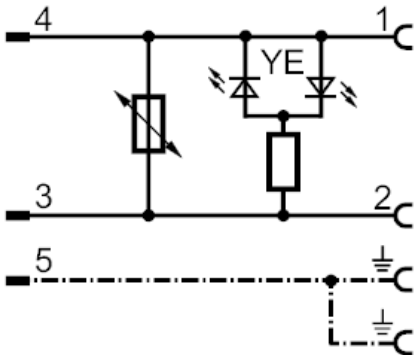

Electrical connection - socket
Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: stainless steel (316L/1.4404)