

E10835




Adapter plug

ESTGH040MSS00,5E04 (PG9)

Article no longer available - archive entry

Alternative articles: E10411
When selecting an alternative article and accessories please note that technical data may differ!

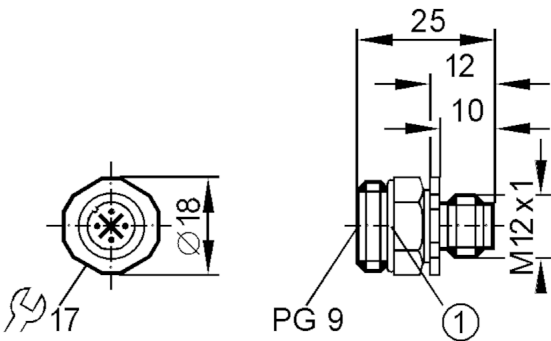

1 O-ring

Electrical data		
Operating voltage	[M]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Mechanical data		
Mounting thread		PG 9
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10835



Adapter plug

ESTGH040MSS00,5E04 (PG9)

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white