




Connecting cable with socket

ADOGK190MSS0010B19

Article no longer available - archive entry

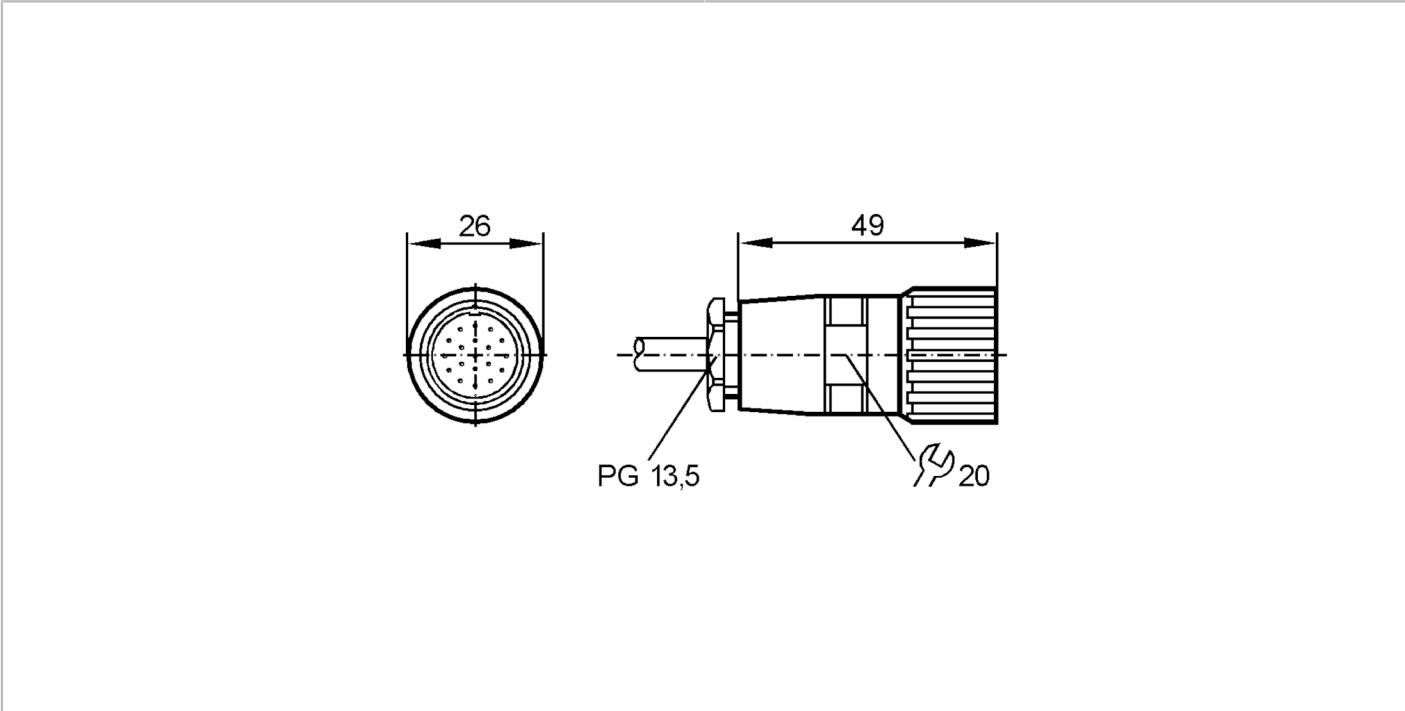

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Dimensions	[mm]	26 x 26 x 49
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Material nut		brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR, black, Ø 11 mm; 16 x 0.5 mm² (64 x Ø 0.1 mm) + 3 x 1.0 mm² (128 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M23; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

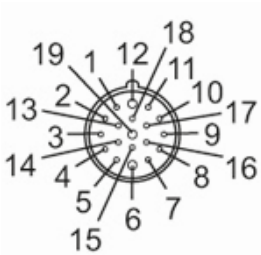

E10948



Connecting cable with socket

ADOGK190MSS0010B19

Connection
