


Connecting cable with socket

ADOAH042ZDS0002E03

Article no longer available - archive entry

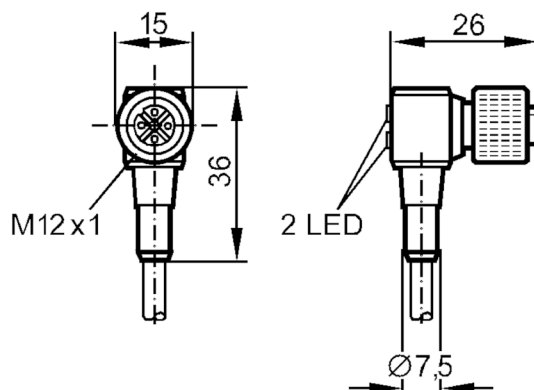

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	NPN
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	36 x 15 x 26
------------	------	--------------

Materials	PUR
-----------	-----

Moulded-body material	PUR
-----------------------	-----

Material nut	diecast zinc, nickel-plated
--------------	-----------------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10007



Connecting cable with socket

ADOAH042ZDS0002E03

Electrical connection


Cable: 2 m, PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Connection

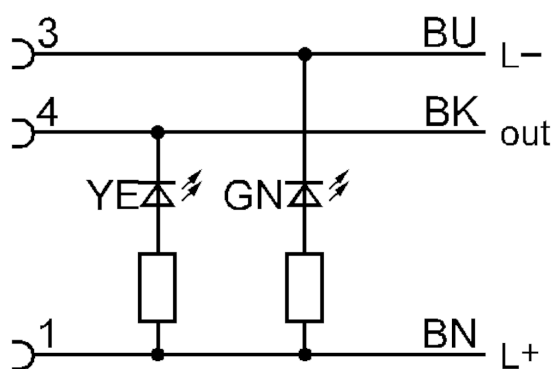

BN =
BK =
BU =

Core colours :
brown
black
blue