

Connecting cable with socket

ADOAF032VAS0025E03

Article no longer available - archive entry



Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	10...30 DC
Protection class	III

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 68

Mechanical data

Dimensions [mm]	18 x 10 x 28
Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (316L/1.4404)

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E11503



Connecting cable with socket

ADOAF032VAS0025E03

Electrical connection


Cable: 25 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

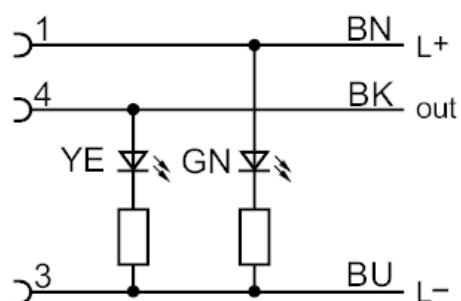

BK =	Core colours :
BN =	black
BU =	brown
	blue