

# E11540




## Connecting cable with socket

ADOGH040MSS0005C04

Article no longer available - archive entry

Alternative articles: EVC527

When selecting an alternative article and accessories please note that technical data may differ!

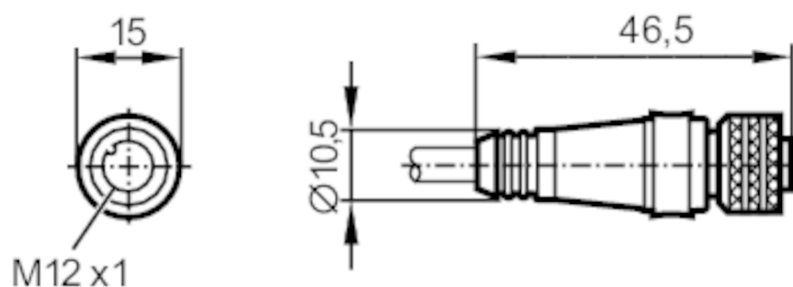

### Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Screened cable
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

### Mechanical data

Weight	[g]	197.6
Dimensions	[mm]	15 x 15 x 46.5
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

### Remarks

Pack quantity	1 pcs.
---------------	--------

# E11540



## Connecting cable with socket

 
ADOGH040MSS0005C04

### Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 5 mm, shielded; 4 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm; Shielded connection cable: screen not connected



### Connection

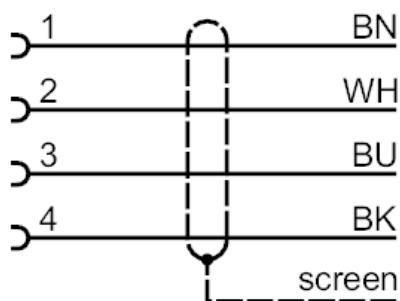

BK =	Core colours :	black
BN =		brown
BU =		blue
WH =		white